




Part Number : [512840600](#)

Product Description : 3.30mm Pitch Wire-to-Board Receptacle Housing, Positive Lock, Dual Row, 6 circuits, Natural

Series Number : 51284

Status : New Business Not Supported

Product Category : Connector Housings

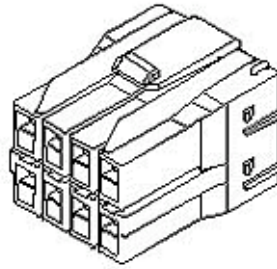

Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	New Business Not Supported
--------	----------------------------

Category	Connector Housings
Series	51284
Description	3.30mm Pitch Wire-to-Board Receptacle Housing, Positive Lock, Dual Row, 6 circuits, Natural
Application	Signal, Wire-to-Board
Product Name	N/A
UPC	756054366899

Physical

Circuits (maximum)	6
Color - Resin	Natural
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1018.600/mg
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.30mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-25° to +85°C