


Part Number : [513470650](#)
Product Description : 3.30mm Pitch Wire-to-Board
Receptacle Housing, Positive Lock, Single Row, 6
Circuits, White
Series Number : 51347
Status : Obsolete
Product Category : Connector Housings

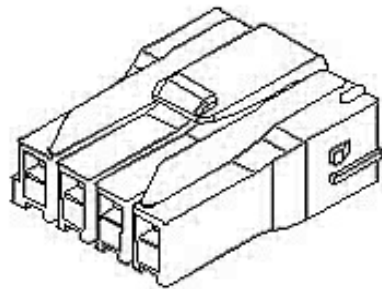

Documents & Resources

Specifications

[PS-51284-001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

Part Details

General

Status	Obsolete
Category	Connector Housings
Series	51347
Description	3.30mm Pitch Wire-to-Board Receptacle Housing, Positive Lock, Single Row, 6 Circuits, White
Application	Signal, Wire-to-Wire
Product Name	N/A
UPC	822348218264

Physical

Circuits (maximum)	6
Color - Resin	Natural
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1171.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.30mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-25° to +85°C

Mates With / Use With

Mates with Part(s)

Description	Part Number

3.30mm Pitch Wire-to-Board Header, Single Row, with Positive Lock, 6 Circuits	<u>558830659</u>
---	------------------

Use with Part(s)

Description	Part Number
3.30mm Pitch Terminal Position Assurance (TPA) Retainers	<u>51348</u>
3.30mm Pitch Female Crimp Terminals	<u>56187</u>

This document was generated on Sep 22, 2025

Obsolete