




Part Number : [732761290](#)

Product Description : N Plug, Straight, Crimp,
RG-141, RG-303, RG-58 and LMR-195 Cable, Brass
Body, Nickel (Ni) Plated, Tray, 50 Ohms

Series Number : 73276

Status : Active

Product Category : RF / Coaxial Connectors

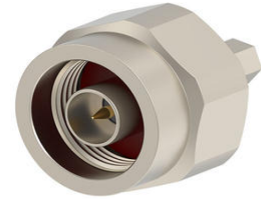

Documents and Resources

Drawings

[732761290 sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)7771- DC (04 Feb 2026)
EU RoHS	Not Reviewed per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

[EU RoHS Certificate of Compliance](#)

[Additional Product Compliance Information](#)

Part Details

General

Status	Active
Category	RF / Coaxial Connectors
Series	73276
Description	N Plug, Straight, Crimp, RG-141, RG-303, RG-58 and LMR-195 Cable, Brass Body, Nickel (Ni) Plated, Tray, 50 Ohms
Application	RF
Product Name	N
Style	Cable
Type	Medium
UPC	822350926119

Electrical

Frequency	11 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 1000 Vrms@Sea Level

Physical

Cable Attachment	Crimp
Gender	Plug
Keying to Mating Part	N/A
Net Weight	41.262/g
Orientation	Straight
Packaging Type	Tray
Panel Mount	No
Panel Mount Method	N/A
PCB Mounting	N/A
Reverse Polar	No

Wire/Cable Type	RG-58, RG-141, RG-303, LMR-195
-----------------	--------------------------------

This document was generated on Feb 26, 2026