




Part Number : [897622272](#)

Product Description : TNC Straight Bulkhead Jack
IP68 to MCX Right-Angle Plug on RG-179 Cable,
57.15mm Length, 75 Ohms

Series Number : 89762

Status : Active

Product Category : RF Cable Assemblies

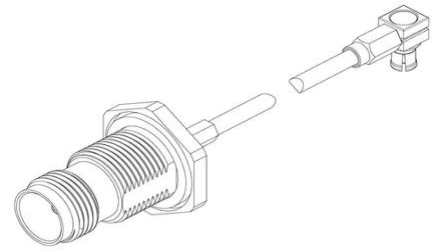

Documents and Resources

Drawings

[897622272_sd.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	RF Cable Assemblies
Series	89762
Description	TNC Straight Bulkhead Jack IP68 to MCX Right-Angle Plug on RG-179 Cable, 57.15mm Length, 75 Ohms
Application	RF
Assembly Configuration	Dual Ended Connectors
Connector to Connector	TNC-to-MCX
Product Name	TNC,MCX
Type	RF Cable Assembly
UPC	193264939251

Electrical

Frequency	6 GHz
Impedance	75Ω

Physical

Cable Length	57.15mm
Gender	Jack/Plug
Material - Metal	Brass, Zinc
Material - Plating Mating	Nickel
Material - Resin	PTFE
Net Weight	18.000/g
Packaging Type	Bag
Single Ended	No
Wire/Cable Type	RG-179

Mates With / Use With

Mates with Part(s)

Description	Part Number
TNC Plugs and Jacks	<u>73216</u>
MCX Plugs and Jacks	<u>73366</u>