


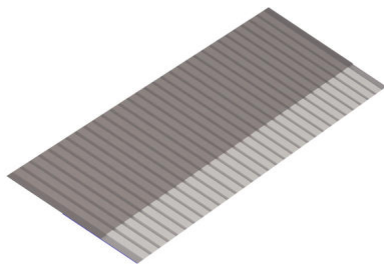

Part Number : [982670473](#)
Product Description : 1.00mm Pitch Premo-Flex FFC
Jumper, Same Side Contacts (Type A), 127.00mm Cable
Length, Tin (Sn) Plating, 30 Circuits
Series Number : 98267
Status : Active
Product Category : Flat-Flexible Cable (FFC)



Documents and Resources

Drawings

- [982670473 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

Specifications

- [PS-98267-001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	98267
Description	1.00mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 127.00mm Cable Length, Tin (Sn) Plating, 30 Circuits
Comments	Contacts on the same side, Type A
Product Name	Premo-Flex FFC Jumper
UPC	756054740804

Electrical

Current - Maximum per Contact	1.2A
Voltage - Maximum	60V AC

Physical

Cable Length	127.00mm
Circuits (Loaded)	30
Contact Layout Type	A (same side)
Design Feature	Extra-Flexible
Material - Plating Mating	Tin
Net Weight	3.430/g
Packaging Type	Bag
Pitch - Mating Interface	1.00mm

Temperature Range - Operating	-40° to +105°C
Termination Style	FFC Connector
Wire/Cable Type	Flat Flexible Cable (FFC)
Wire Size (AWG)	N/A

Mates With / Use With

Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Right-Angle, Bottom Contact, 3.00mm Height, 30 Circuits, Tin-Bismuth Plating	<u>522713079</u>
Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Vertical, 5.75mm Height, 30 Circuits, Tin-Bismuth Plating	<u>526103071</u>
Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Vertical, 5.75mm Height, 30 Circuits, Tin-Bismuth Plating, with Pick-and-Place Tape	<u>526103075</u>
Easy-On FFC/FPC Connector, 1.00mm Pitch, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, 30 Circuits	<u>528083070</u>
Easy-On FFC/FPC Connector, 1.00mm Pitch, Surface Mount, Vertical, Non-ZIF, Tin (Sn) Plating, with Pick-and-Place Polyimide Tape, 30 Circuits	<u>528083071</u>
Easy-On FFC/FPC Connector, 1.00mm Pitch, Slider Series, Right-Angle, Top Contact, 2.70mm Height, 30 Circuits, Tin-Bismuth Plating	<u>522073085</u>
Easy-On FFC/FPC Connector, 1.00mm Pitch, Surface Mount, Right-Angle, Non-ZIF, Top Contact Style, 30 Circuits	<u>527933070</u>

1.00mm Pitch Easy-On FFC/FPC Connector, Vertical, Surface Mount Compatible, Non-ZIF, Kinked PC Tails, 30 Circuits	<u>528063010</u>
1.00mm Pitch Easy-On FFC/FPC Connector, Right-Angle, Non-ZIF, Top Contact Style Receptacle, 30 Circuits	<u>528073010</u>
Easy-On FFC/FPC Connector, 1.00mm Pitch, Surface Mount, Right-Angle, Non-ZIF, Bottom Contact Style, 30 Circuits	<u>528523070</u>