


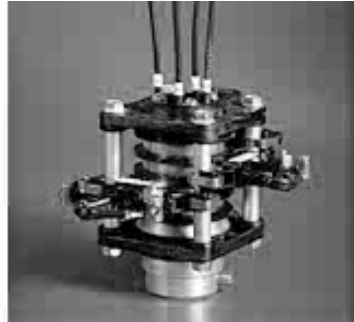

Part Number : [1300920181](#)
Product Description : Aero-Motive Self-Contained Slip Ring, 75A, 4 AWG, 4 Conductors, Bore Size 38.10mm (1.500") Diameter
Series Number : 130092
Status : Active
Product Category : Slip Rings
Engineering Number : SR404

Documents & Resources

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)4165-DC (25 June 2025)
EU RoHS	Not Reviewed per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Slip Rings
Series	130092
Description	Aero-Motive Self-Contained Slip Ring, 75A, 4 AWG, 4 Conductors, Bore Size 38.10mm (1.500") Diameter
Component Type	Self-Contained
Product Name	Aero-Motive
UPC	78678867830

Agency

CSA	LR29921
-----	---------

Electrical

Current - Maximum per Contact	75.0A
Voltage - Maximum	600V

Physical

Center Bore Diameter	38.10mm (1.500")
Mounting Style	Horizontal, Vertical
Number of Conductors	4
Packaging Type	Carton
Speed (RPM)	Continuous 125
Temperature Range - Operating	-40°C to +120°C
Wire Size (AWG)	4