

Honeywell Sensing and Control



Search



narrow your search


Products

- Controls Monitoring and Lighting (354)
- Machine Safety (1726)
- Sensors (7038)
- Switches (9754)

Technology


- Electromechanical (9297)
- Magnetic (526)
- Microstructure (2305)
- Optical/Infrared (1077)
- Thick Film (1764)

Need Help?

Click here to contact us 

102TL2-8 MICRO SWITCH™ Toggle Switches

(Home : Products)

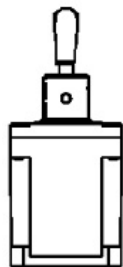

TL Series Toggle Switch, 2 pole, 2 position, IWTS (16-20 Gage) terminal, Standard Lever, Military Part Number MS27785-26

Actual product appearance may vary.


[Sales & Service](#)

[Distributor Inventory](#)

[Overview](#) [Specs](#) [Documentation](#) [Application Notes](#)

Product Specifications

Circuitry/Operating action

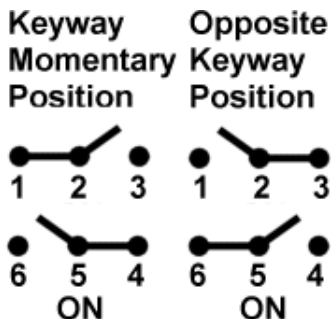

Product Type	MICRO SWITCH™ Toggle Switch
Ampere/Voltage Range (Resistive Load)	0.5 A at 250 Vdc, 0.5 A to 6 A at 0.5 Vac to 230 Vac, 0.5 A to 7.5 A at 0.5 Vdc to 28 Vdc, 0.75 A at 115 Vdc
Circuitry	DPDT
Action	2 position
Circuitry/Operating action	124060
Mounting	Bushing 15/32 in
Termination	IWTS (16-20 Gage)
MIL Spec. Number	MS27785-26
Lever Type	Standard
UL/CSA	L192: 10 A-125, 250, 277 Vac; 1/4 Hp-125 Vac; 1/2 Hp-250, 277 Vac; 3 A-125 Vac "L"
Comment	Silver cadmium oxide contacts
Availability	Global
UNSPSC Code	30211908
UNSPSC Commodity	30211908 Toggle switches
Series Name	TL