



BU-00000-★  
Part # color

★ 0 - Black	5 - Green
2 - Red	6 - Blue
4 - Yellow	9 - White



## CLIPS & INSULATORS



Enlarge

### BU-75K 10 Amp Kelvin Clip

- Electrically isolated jaws
- Silver/gold tip contacts
- Available in black
- Jaw opens 5/16" (7.9mm) max
- [Product Data Sheet](#)
- [Send us your questions about this product](#)

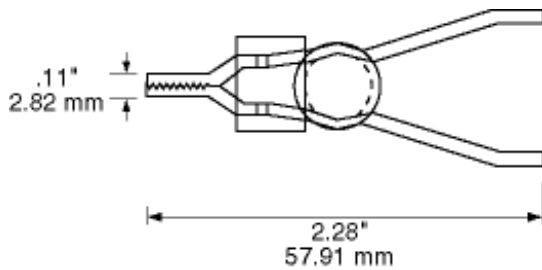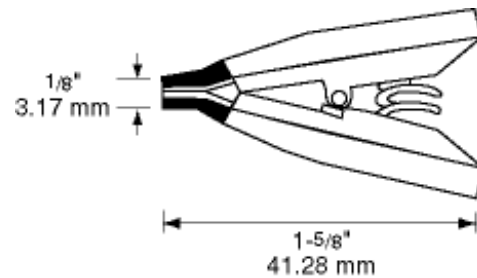

### BU-78K Kelvin Clip - 10 Amp

- Current path for the source; circuit path for the sense
- Gold contacts
- Available in gold
- Jaw opens 1/2" (12mm) max
- [Product Data Sheet](#)
- [Send us your questions about this product](#)



Enlarge

### JP-25182 Telecom Clip with Nickel Plated Bed of Nails

- Nickel silver clip
- 20° offset jaw guards against shorting
- Penetrates insulation on 22AWG wire or larger
- Self-mending insulation upon needle removal
- [Product Data Sheet](#)
- [Send us your questions about this product](#)



Enlarge

### JP-8078 Telecom Clip with Single Needle

- Nickel silver clip
- 20° offset jaw guards against shorting
- Single needle will penetrate insulation on wide range of wire sizes
- [Product Data Sheet](#)
- [Send us your questions about this product](#)



Enlarge

## B-417-\* Insulator for Telecom Clips JP-25182, JP-8078



Enlarge

- Flexible
- Made of rubber
- 20° offset jaw guards against shorting
- Available in black, red, yellow, green
- [Product Data Sheet](#)
- [Send us your questions about this product](#)

---

[Insulated BNCs](#) | [Test Leads](#) | [Insulated Test Accessories](#)  
[Accessories & Probes](#) | [Kits](#) | [Cross Reference](#)

© 2003 Mueller Electric Company. All rights reserved.  
Problems with the site should be reported to the [webmaster](#).