



[Products](#) > [Video](#) > [Phono \(RCA\)](#) > [Phono \(RCA\) Chassis Connectors](#) > NF2D-6


[print](#)

NF2D-6

Phono socket in nickel D-shape housing, blue isolation washers, solder version.

Features & Benefits

- Precisely machined to our demanding quality standards
- Gold plated contacts

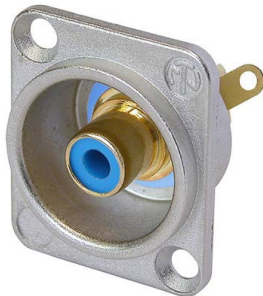

Downloads

- [Product Guide 2012, 03 Plugs+Jacks](#)
- [Drawing NF2D](#)
- [Drawing NF2D](#)
- [3D File NF2D](#)

Technical Information hide

Product	
Title	NF2D-6
Connection Type	RCA
Gender	female
Electrical	
Capacitance between contacts	≤ 9 pF
Contact resistance	<5G mΩ (inner)
Dielectric strength	0,5 kVdc
Insulation resistance	< 5 GΩ
Rated current per contact	16 A
Rated voltage	50 V
Mechanical	
Lifetime	> 2000 mating cycles
Wiring	Solder contacts
Mounting direction	front

Chassis shape	D
Material	
Contact plating	5 µm Au over 5 µm Ni
Contacts	Brass (CuZn39Pb3)
Shell	Zinc diecast (ZnAl4Cu1)
Environmental	
Flammability	UL 94 HB
Standard compliance	IEC 601-14
Protection class	IP 40
Solderability	Complies with IEC 68-2-20
Temperature range	-30 °C to +80 °C

Accessories



CAS-DUMMY



DSS-*



MFD



NDP



SCDP-*



SCDX

