



Deutsche Version

- Home
- About Us
- Products**
 - Audio**
 - Video
 - Lighting
 - Data Connectors
 - Industrial

- Support
- News
- Sitemap

Search


PRODUCTS ONLY

Search

© Neutrik® AG
 All rights reserved
 Legal Notices



NYS-SPP-L1

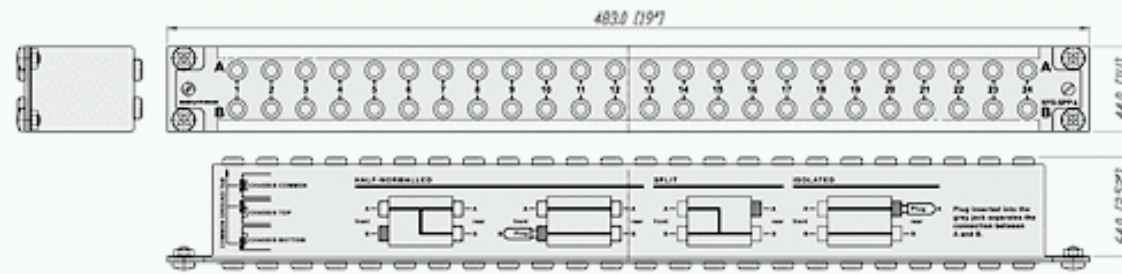

Product

Connector Type Patch Panel

Electrical

Signal Type	AES/EBU Signals (digital)
Contact resistance	< 10 mΩ
Dielectric strength	1 kVdc
Frequencyrange	DC to > 50 MHz
Insulation resistance	> 1 GΩ @ 500 V dc
Channel separation	> 100 dB @ 10 kHz, 600 terminated > 40 dB @ 6 MHz, 110 terminated
Handles Phantom Power	Yes

Mechanical

Insertion force	< 20 N
Withdrawal force	> 10 N
Lifetime	> 10000 mating cycles
Locking device	Retention spring

Material

Contacts	Bronze, tin plated (Jacks)
Contacts	Bronze, tin plated (Switch contacts)
Shell	Steel
Shell	ABS (Jacks)
Front panel	Steel

Environmental

Temperature range	-30 °C to +80 °C
-------------------	------------------

Mobile Cables

Dimensions	482 x 44 mm (19" x 1U)
Depth	64 mm (2.52")
Mating plug	A-Gauge 1/4" plug acc. EIA RS-453