

# NAC3MPB-1-WOT

Chassis connector, power-out, 3/16" flat tab terminals, grey, without insulation divider

The powerCON is a locking 3 conductor equipment AC connector with contacts for line, neutral and pre-mating ground contact. It replaces appliance couplers wherever a very rugged solution in combination with a locking device is needed in order to guarantee a safe power connection.



NAC3MPA-1

NAC3MPA-1-WOT

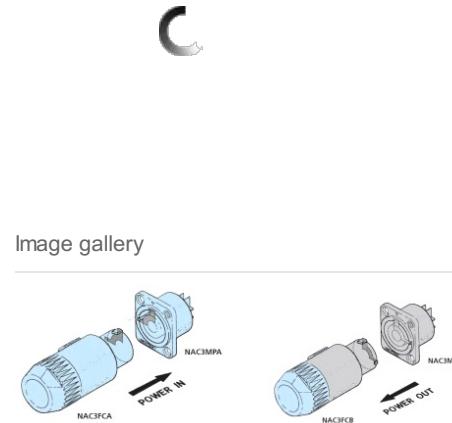


Image gallery

Downloads

- Assembly Instruction - powerCON 20 A
- Product Guide 2013, 07 Circular Connectors
- VDE Certificate powerCON 20 A
- Drawing NAC3MPB-1-WOT
- Drawing NAC3MPB-1-WOT

Links

- UL Certificate (ECBT2.E135070)
- cUL Certificate (ECBT8.E135070)

**Attention:** The powerCON is a connector without breaking capacity, i.e. the powerCON should not be connected or disconnected under load or live!

Features & Benefits

- Locking 20 A / 250 V ac appliance coupler
- 3 contacts for line, neutral and pre-mating safety ground
- Power-in (blue) and power-out (grey) versions with different keying to avoid the possibility of intermating
- Fast and easy twist lock latching system
- Extremely robust and reliable
- Ergonomic design
- User friendly latch design for easy handling
- UL, cUL recognized components
  - VDE certified
  - SEV approved
- Branded with unique hologram - guarantees genuine and authentic Neutrik product

Technical Information [show](#)

Accessories

