


ATM Equivalent – Low Voltage Miniature Automotive, Fast Acting

Features

- Miniature Blade Type
- RoHS Compliant



F-05

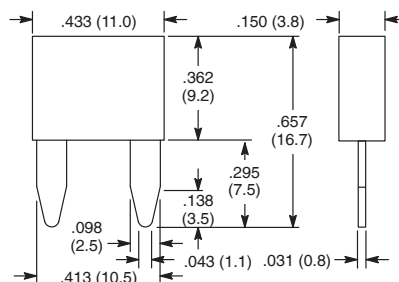

Specifications

Rated Voltage: 32V

Time Current Characteristics:

% of Ampere Rating	Opening Time
110%	4 hours min.
135%	0.75 – 1800 seconds
200%	0.15 – 5 seconds
300%	0.08 seconds max.


Accessories:

Description	NTE Type No.
In-Line Fuse Holder, up to 15A	74-IFHMA15
In-Line Fuse Holder, up to 30A	74-IFHMA30
In-Line Fuse Holder w/LED Light, up to 15A	74-IFHMA15
In-Line Fuse Holder w/LED Light, up to 30A	74-IFHMA30


ATC Equivalent - Low Voltage Automotive, Fast Acting

Features

- Fast Acting
- RoHS Compliant

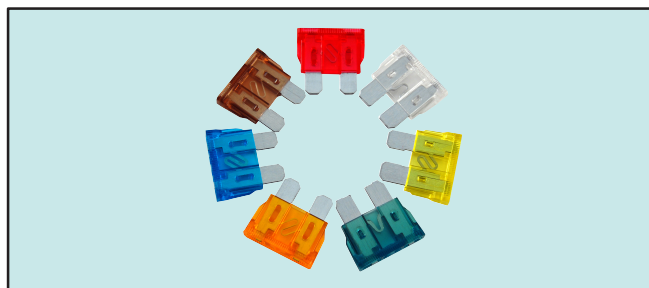

F-06

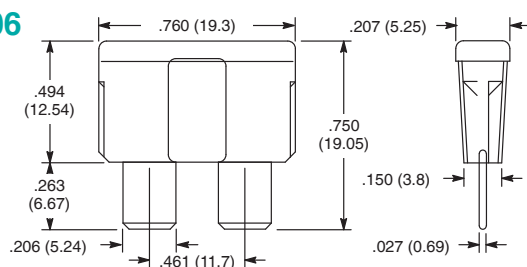

Specifications

Rated Voltage: 32V

Time Current Characteristics:

% of Ampere Rating	Opening Time
110%	100 hours min.
135%	1800 seconds max.
200%	5 seconds max.
300%	0.08 seconds max.

Accessories:

Description	NTE Type No.
In-Line Fuse Holder, up to 15A	74-IFHA15
In-Line Fuse Holder, up to 30A	74-IFHA30
In-Line Fuse Holder w/LED Light, up to 15A	74-IFHAL15
In-Line Fuse Holder w/LED Light, up to 30A	74-IFHAL30