 


HEAT SHRINK INSULATED BUTT CONNECTORS

Specifications

- Waterproof
- Maximum Electrical Rating: 600 Volts
- Shrink Temperature: +150°C
- Operating Temperature: -10° to +105°C
- Terminal Material: Copper Tube
- Plating: Electro Tin Plated
- Insulated Material: Heat Shrinkable Tube



Ordering Information:


Wire Range AWG / mm ²	NTE Part Number	Dimensions inch(mm)				Insulated Color
		F	L	D	d	
26 – 24 AWG 0.2 – 0.4mm ²	76-HIBC26	.472 (12.0)	.945 (24.0)	.082 (2.1)	.047 (1.2)	Transparent
22 – 18 AWG 0.5 – 1.5mm ²	76-HIBC22	.591 (15.0)	1.457 (37.0)	.177 (4.5)	.063 (1.6)	Red
16 – 14 AWG 1.5–2.5mm ²	76-HIBC16	.591 (15.0)	1.457 (37.0)	.217 (5.5)	.091 (2.3)	Blue
12 – 10 AWG 4–6mm ²	76-HIBC12	.591 (15.0)	1.614 (41.0)	.256 (6.5)	.142 (3.6)	Yellow

HEAT SHRINK INSULATED SOLDER BUTT CONNECTORS

Specifications

- Waterproof Hot Melt Adhesive
- Maximum Electrical Rating: 1k Volts
- Shrink Temperature: +60°C
- Starting Temperature of Solder Melt: +138°C
- Operating Temperature: -55° to +125°C
- Terminal Material: Tin
- Plating: None
- Insulated Material: Heat Shrinkable Tube

Photo Not
Available

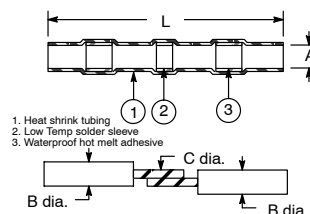

Ordering Information:

	Wire Range AWG / mm ²	NTE Part Number	Product Dimensions inch(mm)		Wire Dimensions inch(mm)			Insulated Color
			A (min)	L (max)	B (min)	B (max) C (min)	C (min)	
NEW	26 – 24 AWG 0.2 – 0.4mm ²	76-HISBC26	.067 (1.7)	1.024 (26.0)	.039 (1.0)	.067 (1.7)	.030 (0.76)	Transparent
NEW	22 – 18 AWG 0.5 – 1.5mm ²	76-HISBC22	.106 (2.7)	1.575 (40.0)	.055 (1.4)	.106 (2.7)	.047 (1.2)	Red
NEW	16 – 14 AWG 1.5–2.5mm ²	76-HISBC16	.177 (4.5)	1.575 (40.0)	.090 (2.3)	.177 (4.5)	.079 (2.0)	Blue
NEW	12 – 10 AWG 4–6mm ²	76-HISBC12	.268 (6.8)	1.614 (41.0)	.146 (3.7)	.268 (6.8)	.134 (3.4)	Yellow