



7.7" & 9.8" A-blade Axial Fans




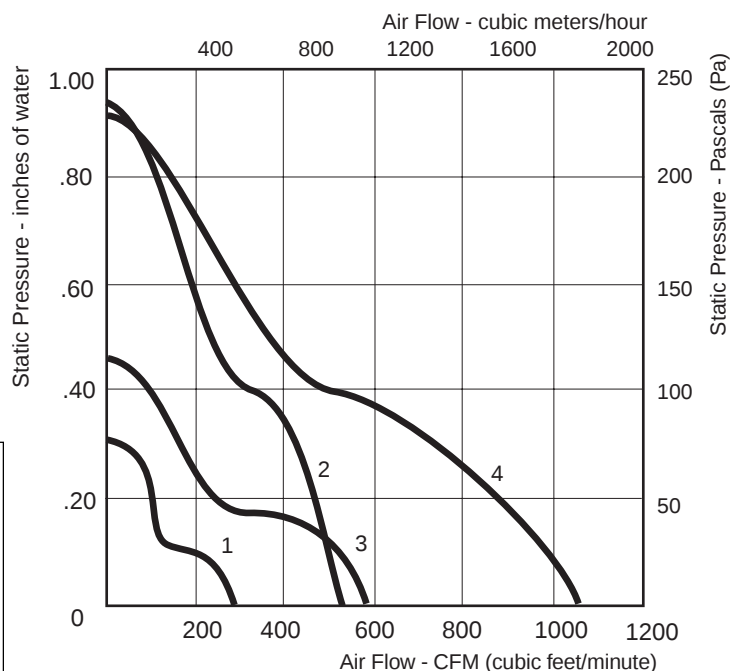


- Blades permanently attached to the external rotor motor for optimum motor cooling and reliable, long life operation
- Select Fan, Fan with Guard, Fan in round or square housing

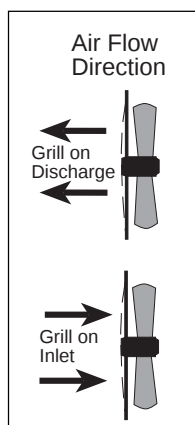

Dimensions

Type	Dimensions - inches (mm)							
	a	b	c	d	e	f	g	h
W...200	7.7 (195)	7.9 (200)	11.0 (280)	3.1 (80)	9.8 (250)	0.3 (7)	12.3 (312)	10.2 (260)
W...250	9.8 (250)	10.0 (254)	12.6 (320)	3.3 (85)	11.6 (295)	0.3 (7)	14.6 (370)	12.6 (320)

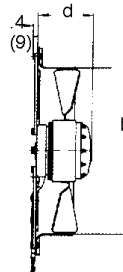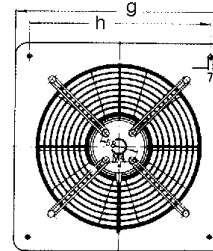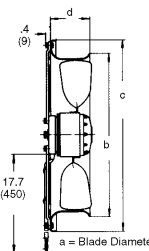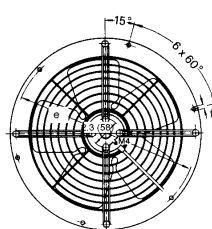

Part Numbers in this table: ROUND Venturi Housing with Grill on Discharge

Curve Number	PART NUMBER*	Volts	Hertz	Watts	Grill	Blade Dia (in)	CFM @ 0"	dBa	Temp. Max °C	Wgt. (lbs.)	Wiring Dgm#	Capacitor (µf)
1	W4S200-CA16-51	115	60	34	Dischg	8	262	53	65	3	B	none
1	W4S200-CA02-51	230	50/60	34	Dischg	8	262	53	65	3	B	none
2	W2E200-CE63-51	115	50/60	82	Dischg	8	520	69	75	6	A	6
2	W2E200-CE31-51	230	50/60	82	Dischg	8	520	69	75	6	A	1.5
3	W4S250-CA20-51	115	60	80	Dischg	10	589	62	50	4	B	none
3	W4S250-CA02-51	230	50/60	67	Dischg	10	589	62	40	4	B	none
4	W2E250-CB13-51	115	60	190	Dischg	10	1060	71	50	7	A	16
4	W2E250-CB05-51	230	60	190	Dischg	10	1060	71	50	7	A	4

* Air Flow Direction listed has grill on discharge and a blade rotation of L.

ROUND Housing, Grill on Inlet		SQUARE Plate, Grill Discharge		SQUARE Plate, Grill on Inlet	
115 V	230V	115V	230V	115V	230V
W4S200-CA16-52	W4S200-CA02-52	W4S200-DA16-51	W4S200-DA02-51	W4S200-DA16-52	W4S200-DA02-52
W2E200-CE63-52	W2E200-CE31-52	W2E200-DE63-51	W2E200-DE31-51	W2E200-DE63-52	W2E200-DE31-52
W4S250-CA20-52	W4S250-CA02-52	W4S250-DA20-51	W4S250-DA02-51	W4S250-DA20-52	W4S250-DA02-52
W2E250-CB13-52	W2E250-CB05-52	W2E250-DB13-51	W2E250-DB05-51	W2E250-DB13-52	W2E250-DB05-52