

Cable sleeve - CES-LRG-BK-20 - 0801631

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

Large, slotted cable sleeves suitable for cables with a diameter of 19 ... 20 mm, material: NBR




Product Description

Slotted cable sleeve

Slotted sleeves for accommodating pre-assembled cables and lines with a diameter of 19 mm ... 20 mm, can be used in CES sealing frames.

Key Commercial Data

| | |
|--------------------------------------|---|
| Packing unit | 1 pc |
| Minimum order quantity | 10 pc |
| GTIN |  4 046356 674300 |
| GTIN | 4046356674300 |
| Weight per Piece (excluding packing) | 40.000 g |
| Custom tariff number | 40169300 |
| Country of origin | Taiwan |

Technical data

Dimensions

| | |
|-------------------------|--------------------|
| External cable diameter | 1x 19 mm ... 20 mm |
| Length | 53 mm |
| Width | 39 mm |
| Height | 17 mm |

Ambient conditions

| | |
|---------------------------------|----------------------------|
| Degree of protection | IP54 |
| Ambient temperature (operation) | -40 °C ... 125 °C (static) |

Cable sleeve - CES-LRG-BK-20 - 0801631

Technical data

General


| | |
|-------------------|-------|
| No. of conductors | 1 |
| Material | NBR |
| | NBR |
| Color | black |

Environmental Product Compliance

| | |
|------------|---|
| China RoHS | Environmentally friendly use period: unlimited = EFUP-e |
| | No hazardous substances above threshold values |

Drawings

Dimensional drawing

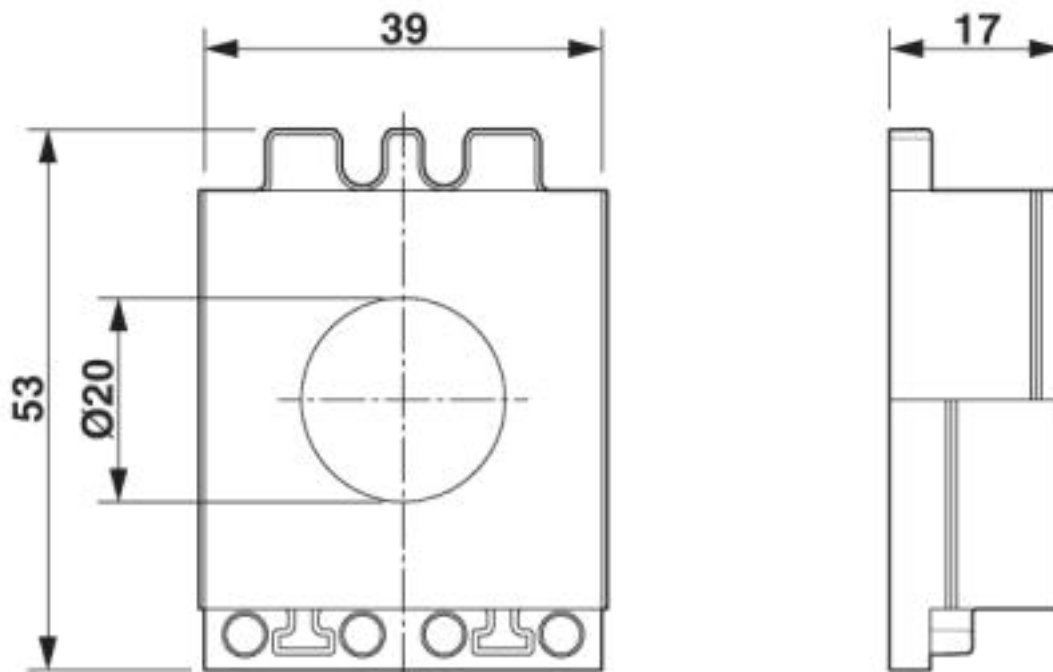

Dimensional drawing

Classifications

eCl@ss

| | |
|---------------|----------|
| eCl@ss 10.0.1 | 27144425 |
| eCl@ss 4.0 | 27081000 |
| eCl@ss 4.1 | 27081000 |

Cable sleeve - CES-LRG-BK-20 - 0801631

Classifications

eCl@ss

| | |
|------------|----------|
| eCl@ss 5.0 | 27081000 |
| eCl@ss 5.1 | 27081000 |
| eCl@ss 6.0 | 27081000 |
| eCl@ss 7.0 | 27069220 |
| eCl@ss 8.0 | 27069220 |
| eCl@ss 9.0 | 27144425 |

ETIM

| | |
|----------|----------|
| ETIM 3.0 | EC000879 |
| ETIM 4.0 | EC000451 |
| ETIM 5.0 | EC000451 |
| ETIM 6.0 | EC000451 |
| ETIM 7.0 | EC000451 |

UNSPSC

| | |
|---------------|----------|
| UNSPSC 6.01 | 30212109 |
| UNSPSC 7.0901 | 39121708 |
| UNSPSC 11 | 39121708 |
| UNSPSC 12.01 | 39121708 |
| UNSPSC 13.2 | 39121448 |
| UNSPSC 18.0 | 39121448 |
| UNSPSC 19.0 | 39121448 |
| UNSPSC 20.0 | 39121448 |
| UNSPSC 21.0 | 39121448 |

Approvals

Approvals

Approvals

GL

Ex Approvals

Approval details

Cable sleeve - CES-LRG-BK-20 - 0801631

Approvals

| | | | |
|----|---|---|------------|
| GL |  | https://approvalfinder.dnvgl.com/ | 1391415 HH |
|----|---|---|------------|