

## Housing - HC-COM-BAWS-PL-BK - 1012433


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Panel mounting base COM, with single locking latch, material: PA, height: 36 mm, cable gland: none, support sleeve: no, Standard



### Key Commercial Data

Packing unit	1 pc
GTIN	 4 0 5 5 6 2 6 4 8 8 5 9 2
GTIN	4055626488592
Weight per Piece (excluding packing)	40.000 g
Custom tariff number	85389099
Country of origin	China

### Technical data

#### Dimensions

Height	36 mm
Width	49.5 mm
Length	64 mm
Length of the assembly cutout	25.5 mm
Width of the assembly cutout	23.5 mm

#### Ambient conditions

Degree of protection (IP)	IP66
Ambient temperature (operation)	-40 °C ... 125 °C

#### General

Size	COM
------	-----

# Housing - HC-COM-BAWS-PL-BK - 1012433

## Technical data

### General


Housing type	Panel mounting base
Color	black
Locking type	with single locking latch
Screw connection	none
Housing material	PA
Seal material	NBR
Material lock	PA
Flammability rating according to UL 94	V0 (Housing)
	V0 (Interlock)

### Environmental Product Compliance


China RoHS	Environmentally Friendly Use Period = 50 years
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"

## Drawings

Dimensional drawing

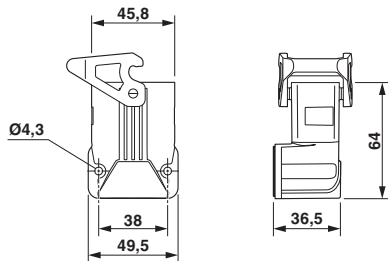

Dimensional drawing

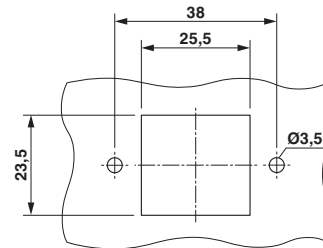

Mounting cutout

## Classifications

### eCl@ss

eCl@ss 10.0.1	27440202
eCl@ss 11.0	27440202
eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27261200
eCl@ss 6.0	27261200
eCl@ss 7.0	27440202

# Housing - HC-COM-BAWS-PL-BK - 1012433

## Classifications

### eCl@ss

eCl@ss 9.0	27440202
------------	----------

### ETIM

ETIM 4.0	EC000437
ETIM 6.0	EC000437
ETIM 7.0	EC000437

### UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261501
UNSPSC 18.0	31261501
UNSPSC 19.0	31261501
UNSPSC 20.0	31261501
UNSPSC 21.0	31261501

## Approvals

### Approvals

Approvals

EAC

Ex Approvals

### Approval details

EAC		RU C- DE.BL08.B.00511
-----	--	--------------------------