

Housing - H5S:D1FF:3C5FF:DP - 1046945

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYPORT B48 panel mounting base, with single screw lock, with plastic protective cover, with stainless steel front plate connections 3x RJ45 CAT5e (female/female), 1x D-SUB 9 (female/female), 1x 120 V duplex outlet 20 A

Your advantages

- good shielding in the event of electromagnetic interference



Key Commercial Data

Packing unit	1 pc
Weight per Piece (excluding packing)	840.000 g

Technical data

Dimensions

Height	39.4 mm
Width	99.2 mm
Length	162 mm

Ambient conditions

Degree of protection of housing (IP)	IP65
Ambient temperature (operation)	-40 °C ... 125 °C (Housing)

General

Size	B48
Color	gray aluminum
Torque	1.5 Nm ... 2 Nm (Mounting screw)
Protective cover	yes
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	uncoated

Housing - H5S:D1FF:3C5FF:DP - 1046945

Technical data

General

Material lock	Stainless steel
Material, protective cover	PA

Mechanical characteristics

Type	B48
Contact insert design	with 3x RJ45 Cat 5E Ethernet Socket/socket, snap-in slot locking
	with 1x D-SUB 9 socket/socket #4-40 UNC bolts
	with 1x 120 V AC outlet

Electrical characteristics


Rated voltage (III/3)	max. 125 V AC (AC outlet, cULus)
Rated current	max. 1.5 A DC (RJ45)

Environmental Product Compliance

China RoHS	Environmentally Friendly Use Period = 50 years
	For details about hazardous substances go to tab "Downloads", Category "Manufacturer's declaration"


Drawings

Dimensional drawing

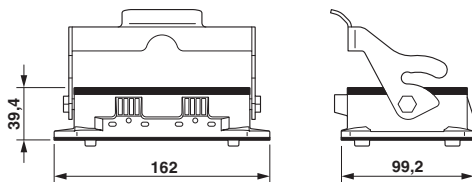

Dimensional drawing

Dimensional drawing

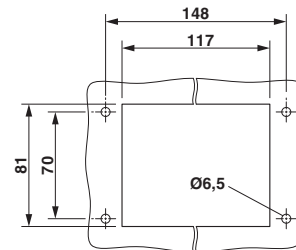

Mounting cutout

Classifications

eCl@ss

eCl@ss 10.0.1	27440101
eCl@ss 11.0	27440101
eCl@ss 9.0	27440101

ETIM

ETIM 6.0	EC002636
ETIM 7.0	EC002636

Housing - H5S:D1FF:3C5FF:DP - 1046945

Accessories

Accessories

Connector

Connector - C-SCFFI 2,5/6,3X0,8 - 3240547



Slip-on sleeve, fully isolated, blue, 1.5 ... 2.5 mm², for plug 6.3 x 0.8 mm

Connector - C-SCFFI 6/6,3X0,8 - 3240541



Slip-on sleeve, fully insulated, yellow, 4 ... 6 mm², for 6.3 x 0.8 mm plugs

Connector - C-SCFFI 1,5/6,3X0,8 - 3240538



Slip-on sleeve, fully isolated, red, 0.5 ... 1.5 mm², for plug 6.3 x 0.8 mm

Connector - C-SCFFI 2,5/4,8X0,8 - 3240540



Slip-on sleeve, fully isolated, blue, 1.5 ... 2.5 mm², for plug 4.8 x 0.8 mm

Connector - C-SCFFI 2,5/4,8X0,5 - 3240539



Slip-on sleeve, fully isolated, blue, 1.5 ... 2.5 mm², for plug 4.8 x 0.5 mm

Housing - H5S:D1FF:3C5FF:DP - 1046945

Accessories

Connector - C-SCFFI 1,5/4,8X0,8 - 3240537



Slip-on sleeve, fully isolated, red, 0.5 ... 1.5 mm², for plug 4.8 x 0.8 mm

Connector - C-SCFFI 1,5/4,8X0,5 - 3240536



Slip-on sleeve, fully isolated, red, 0.5 ... 1.5 mm², for plug 4.8 x 0.5 mm
