

## Housing - HC-COM-HHFS-1STM25-EL-AL - 1078592

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Sleeve housing COM, for single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, lateral, height: 68 mm, cable gland: none, support sleeve: no, 1x M25, Standard



### Key Commercial Data

Packing unit	1 pc
GTIN	 4 055626 794105
GTIN	4055626794105
Custom tariff number	76169990
Country of origin	China

### Technical data

#### Dimensions

Height	68 mm
Width	39 mm
Length	48.8 mm

#### Ambient conditions

Degree of protection (IP)	IP66
Ambient temperature (operation)	-40 °C ... 125 °C

#### General

Size	COM
Housing type	Sleeve housing
Color	gray aluminum
Locking type	for single locking latch

# Housing - HC-COM-HHFS-1STM25-EL-AL - 1078592


## Technical data

### General

No. of cable outlets	1
Cable outlet	lateral
Screw connection	none
Type of the screw connection	1x M25
Housing material	Die-cast aluminum, salt water resistant

## Drawings

Dimensional drawing

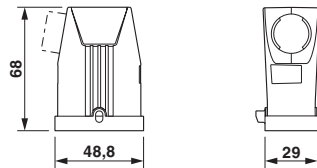

## Classifications

### eCl@ss

eCl@ss 10.0.1	27440202
eCl@ss 11.0	27440202
eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27261200
eCl@ss 6.0	27261200
eCl@ss 7.0	27440202
eCl@ss 9.0	27440202

### ETIM

ETIM 4.0	EC000437
ETIM 6.0	EC000437
ETIM 7.0	EC000437

### UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502

# Housing - HC-COM-HHFS-1STM25-EL-AL - 1078592

## Classifications

### UNSPSC

UNSPSC 12.01	31261502
UNSPSC 13.2	31261501
UNSPSC 18.0	31261501
UNSPSC 19.0	31261501
UNSPSC 20.0	31261501
UNSPSC 21.0	31261501

## Approvals

### Approvals

#### Approvals

UL Recognized / cUL Recognized / EAC / cULus Recognized

#### Ex Approvals

### Approval details

UL Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	E255026
---------------	--	---	---------

cUL Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	E255026
----------------	--	---	---------

EAC			RU C- DE.BL08.B.00511
-----	--	--	--------------------------

cULus Recognized			
------------------	--	--	--

## Accessories

### Accessories

## Housing - HC-COM-HHFS-1STM25-EL-AL - 1078592

### Accessories

Corrugated pipe screw connection

Screw connection - WP-G HF IP66 M25 BK - 3240899



Cable gland, metric thread, IP66 protection, straight

---

Screw connection - WP-G HF IP69K M25 BK - 3240885



Cable gland, metric thread, IP68/69k protection, straight

---

Screw connection - WP-GA HF IP66 M25 BK - 3240927



Cable gland, metric thread, IP66 protection, angled

---

Screw connection - WP-GA HF IP69K M25 BK - 3240913



Cable gland, metric thread, IP68/69k protection, angled

---

Screw connection - WP-GR HF IP66 M25 BK - 3240955



Cable gland, metric thread, IP66 protection, with strain relief

---

## Housing - HC-COM-HHFS-1STM25-EL-AL - 1078592

### Accessories

Screw connection - WP-GR HF IP69K M25 BK - 3240941



Cable gland, metric thread, IP68/69k protection, with strain relief

---

Screw connection - WP-G PP HF M25 - 3240999



Cable gland made from PP with metric thread, IP65 protection

---

Screw connection - WP-GT PP HF M25 - 3241013



Cable gland made from PP with metric thread, rotatable, IP54 protection

---

Screw connection - WP-G BRASS IP40 M25 - 3241048



Cable gland made from brass with metric thread, IP40 protection

---

Screw connection - WP-GT BRASS M25 - 3241034



Cable gland made from brass with metric thread, rotatable, IP40 protection

---

## Housing - HC-COM-HHFS-1STM25-EL-AL - 1078592

### Accessories

Screw connection - WP-G BRASS IP65 M25 - 3241062



Cable gland made from brass with metric thread, IP65 protection