

Housing - HC-COM-CHWS-1TTM25-EL-AL - 1078595


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Coupling housings COM, with single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, straight, height: 68 mm, cable gland: none, support sleeve: no, 1x M25, Standard



Key Commercial Data

Packing unit	1 pc
GTIN	 4 0 5 5 6 2 6 7 9 4 1 3 6
GTIN	4055626794136
Weight per Piece (excluding packing)	80.000 g
Custom tariff number	85389099
Country of origin	China

Technical data

Dimensions

Height	68 mm
Width	39 mm
Length	48.8 mm

Ambient conditions

Degree of protection (IP)	IP66
Ambient temperature (operation)	-40 °C ... 125 °C

General

Size	COM
Housing type	Coupling housings
Color	gray aluminum

Housing - HC-COM-CHWS-1TTM25-EL-AL - 1078595


Technical data

General

Locking type	with single locking latch
No. of cable outlets	1
Cable outlet	straight
Screw connection	none
Type of the screw connection	1x M25
Housing material	Die-cast aluminum, salt water resistant
Material lock	PA
Flammability rating according to UL 94	V0 (Interlock)

Drawings

Dimensional drawing

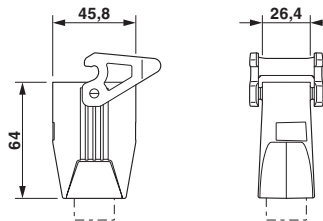

Classifications

eCl@ss

eCl@ss 10.0.1	27440202
eCl@ss 11.0	27440202
eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424
eCl@ss 5.1	27261200
eCl@ss 6.0	27261200
eCl@ss 7.0	27440202
eCl@ss 9.0	27440202

ETIM

ETIM 4.0	EC000437
ETIM 6.0	EC000437
ETIM 7.0	EC000437

Housing - HC-COM-CHWS-1TTM25-EL-AL - 1078595

Classifications

UNSPSC

UNSPSC 6.01	31261502
UNSPSC 7.0901	31261502
UNSPSC 11	31261502
UNSPSC 12.01	31261502
UNSPSC 13.2	31261501
UNSPSC 18.0	31261501
UNSPSC 19.0	31261501
UNSPSC 20.0	31261501
UNSPSC 21.0	31261501

Approvals

Approvals

Approvals

UL Recognized / cUL Recognized / EAC / cULus Recognized


Ex Approvals

Approval details

UL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E255026
---------------	---	---	---------

cUL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E255026
----------------	---	---	---------

EAC			RU C- DE.BL08.B.00511
-----	---	--	--------------------------

cULus Recognized			
------------------	---	--	--

Housing - HC-COM-CHWS-1TTM25-EL-AL - 1078595

Accessories

Accessories

Corrugated pipe screw connection

Screw connection - WP-G HF IP66 M25 BK - 3240899



Cable gland, metric thread, IP66 protection, straight

Screw connection - WP-G HF IP69K M25 BK - 3240885



Cable gland, metric thread, IP68/69k protection, straight

Screw connection - WP-GA HF IP66 M25 BK - 3240927



Cable gland, metric thread, IP66 protection, angled

Screw connection - WP-GA HF IP69K M25 BK - 3240913



Cable gland, metric thread, IP68/69k protection, angled

Screw connection - WP-GR HF IP66 M25 BK - 3240955



Cable gland, metric thread, IP66 protection, with strain relief

Housing - HC-COM-CHWS-1TTM25-EL-AL - 1078595

Accessories

Screw connection - WP-GR HF IP69K M25 BK - 3240941



Cable gland, metric thread, IP68/69k protection, with strain relief

Screw connection - WP-G PP HF M25 - 3240999



Cable gland made from PP with metric thread, IP65 protection

Screw connection - WP-GT PP HF M25 - 3241013



Cable gland made from PP with metric thread, rotatable, IP54 protection

Screw connection - WP-G BRASS IP40 M25 - 3241048



Cable gland made from brass with metric thread, IP40 protection

Screw connection - WP-GT BRASS M25 - 3241034



Cable gland made from brass with metric thread, rotatable, IP40 protection

Housing - HC-COM-CHWS-1TTM25-EL-AL - 1078595

Accessories

Screw connection - WP-G BRASS IP65 M25 - 3241062



Cable gland made from brass with metric thread, IP65 protection
