

Cable sleeve - CES-SRG-BK-4X6 - 1410152

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Small, slotted cable sleeves suitable for four cables with a diameter of 5 ... 6 mm, material: NBR

Product Description

drilled special sleeve in IP44

Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 046356 776363
GTIN	4046356776363
Weight per Piece (excluding packing)	8.000 g
Custom tariff number	40169300
Country of origin	Poland

Technical data

Dimensions

External cable diameter	4x 5 mm ... 6 mm
Length	29.5 mm
Width	19.5 mm
Height	17 mm

Ambient conditions

Degree of protection	IP54 (Observe the assembly instructions)
Ambient temperature (operation)	-40 °C ... 125 °C (static)

Cable sleeve - CES-SRG-BK-4X6 - 1410152

Technical data

General


Product description	drilled special sleeve in IP44
No. of conductors	4
Material	NBR
Color	black
Installation instructions	IP54: for vertical sealing frame mounting/for horizontal sealing frame mounting (downward cable outlet direction).

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

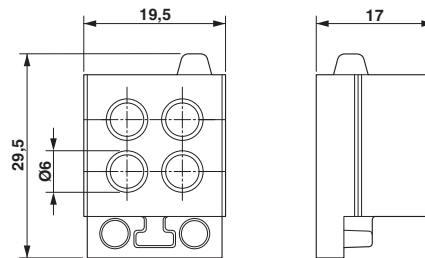

Dimensional drawing