

Reducing adapter - REDUC-K-KV-M32/M25 BK - 1410712

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Reducing adapter, plastic, M32 to M25, including O-ring

RoHS

Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 046356 873246
GTIN	4046356873246
Custom tariff number	39269097
Country of origin	Germany

Technical data

Dimensions

Length	16 mm
Length without connecting thread	6 mm
Connecting thread diameter	32 mm
Hexagon angular dimension	40 mm
Length of the connecting thread	10 mm

Ambient conditions

Degree of protection	IP65 (Depends on the screw connection used)
Ambient temperature (operation)	-30 °C ... 100 °C

General

Material	Polyamide fiberglass reinforced
----------	---------------------------------

Reducing adapter - REDUC-K-KV-M32/M25 BK - 1410712

Technical data

General

Outer thread	M32
Internal thread	M25
Flammability rating according to UL 94	HB
Color	black

Standards and Regulations


Flammability rating according to UL 94	HB
--	----

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

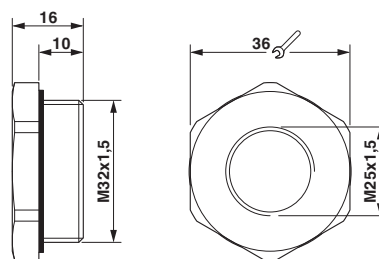

Dimensional drawing