

Reducing adapter - REDUC-K-KV-M40/M32 BK - 1410738

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Reducing adapter, plastic, M40 to M32, including O-ring

RoHS

Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 046356 873192
GTIN	4046356873192
Weight per Piece (excluding packing)	14.000 g
Custom tariff number	39269097
Country of origin	Germany

Technical data

Dimensions

Length	16 mm
Length without connecting thread	6 mm
Connecting thread diameter	40 mm
Hexagon angular dimension	50.5 mm
Length of the connecting thread	10 mm

Ambient conditions

Degree of protection	IP65 (Depends on the screw connection used)
Ambient temperature (operation)	-30 °C ... 100 °C

General

Reducing adapter - REDUC-K-KV-M40/M32 BK - 1410738

Technical data

General

Material	Polyamide fiberglass reinforced
Outer thread	M40
Internal thread	M32
Flammability rating according to UL 94	HB
Color	black

Standards and Regulations


Flammability rating according to UL 94	HB
--	----

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

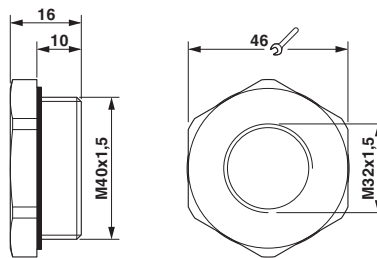

Dimensional drawing

Classifications

eCl@ss

eCl@ss 4.0	27141209
eCl@ss 4.1	27141209
eCl@ss 5.0	27149109
eCl@ss 5.1	27149109
eCl@ss 6.0	27149109
eCl@ss 7.0	27149109
eCl@ss 8.0	27149109
eCl@ss 9.0	27144432

ETIM

ETIM 4.0	EC000441
----------	----------

Reducing adapter - REDUC-K-KV-M40/M32 BK - 1410738

Classifications

ETIM

ETIM 5.0	EC000441
ETIM 6.0	EC000441

UNSPSC

UNSPSC 6.01	30211808
UNSPSC 7.0901	39121408
UNSPSC 11	39121408
UNSPSC 12.01	39121408
UNSPSC 13.2	39121311