

Cable gland - HC-D-G-M25-PLRBK - 1411351

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



EVO plastic cable gland with bayonet locking, for housing series D, size M25, cable diameter: 9 ... 17 mm.

RoHS

Key Commercial Data

Packing unit	1 STK
GTIN	 4 046356 929226
GTIN	4046356929226
Weight per Piece (excluding packing)	40.000 g
Custom tariff number	39269097
Country of origin	Poland

Technical data

Dimensions

Wrench size, union nut	26 mm
External cable diameter	9 mm ... 17 mm

Ambient conditions

Degree of protection	IP66
	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 100 °C

General

Type of the screw connection	M25
No. of conductors	1
Material	PA

Cable gland - HC-D-G-M25-PLRBK - 1411351

Technical data

General

Cable gland material	PA
Material, pressure screw	PA
Seal material	NBR
Cable seal material	NBR
Flammability rating according to UL 94	V0 / V2
Shielded	No
Tightening torque, union nut	5.00 Nm
Color	black
Assembly instructions	Bayonet locking max. 3x can be removed

Standards and Regulations


Flammability rating according to UL 94	V0 / V2
--	---------

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

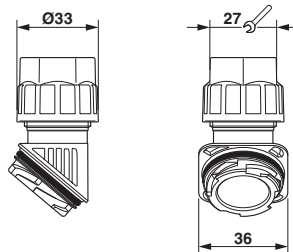

Dimensional drawing

Classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 8.0	27149109
eCl@ss 9.0	27144432

ETIM

ETIM 4.0	EC000441
----------	----------

Cable gland - HC-D-G-M25-PLRBK - 1411351

Classifications

ETIM

ETIM 5.0	EC000441
ETIM 6.0	EC000441

UNSPSC

UNSPSC 13.2	39121311
-------------	----------

Approvals

Approvals

Approvals

EAC / EAC

Ex Approvals

Approval details

EAC		RU C- DE.AI30.B.01102
-----	--	--------------------------

EAC		RU C- DE.AI30.B.01102
-----	--	--------------------------

Accessories

Accessories

Corrugated pipe screw connection

Corrugated tube screw connection - WP-GR HF CTA M25 BK - 3241221



Corrugated pipe adapter, with M25 internal thread, straight, black, IP66, for connecting corrugated pipes to HEAVYCON EVO plastic cable glands or ADVANCE plastic housing.
