

Adapter - HC-D-TA-M25-PLRBK - 1411352

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



EVO plastic adapter with bayonet locking, for EVO housing series D, for M25 screw connections.



Key Commercial Data

Packing unit	1 STK
GTIN	 4 046356 929233
GTIN	4046356929233
Weight per Piece (excluding packing)	20.000 g
Custom tariff number	39269097
Country of origin	Poland

Technical data

Ambient conditions

Degree of protection	IP66 (DIN IEC 60529)
Ambient temperature (operation)	-40 °C ... 125 °C

General

Type of the screw connection	M25
Material	PA
Housing material	PA
Seal material	NBR
Flammability rating according to UL 94	V2
Thread type on seal side	M25

Standards and Regulations

Adapter - HC-D-TA-M25-PLRBK - 1411352

Technical data

Standards and Regulations


Flammability rating according to UL 94	V2
--	----

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

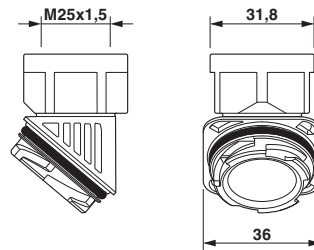

Dimensional drawing

Classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 8.0	27440202
eCl@ss 9.0	27440192

ETIM

ETIM 4.0	EC000516
ETIM 5.0	EC000516
ETIM 6.0	EC000437

UNSPSC

UNSPSC 13.2	31261501
-------------	----------

Approvals

Approvals

Adapter - HC-D-TA-M25-PLRBK - 1411352

Approvals


Approvals

EAC / EAC

Ex Approvals

Approval details

EAC		RU C- DE.AI30.B.01102
-----	---	--------------------------

EAC		RU C- DE.AI30.B.01102
-----	---	--------------------------

Accessories

Accessories

Full screw connection

Cable gland - G-INS-M25-M68N-PNES-BK - 1411134



Cable gland, cable gland material: PA, external cable diameter 11 mm ... 17 mm, shielding: No, connecting thread: M25 x 1.5, color: jet black RAL 9005

Cable gland - G-INS-M25-L68N-PNES-BK - 1424482



Cable gland, cable gland material: PA, external cable diameter 13 mm ... 18 mm, shielding: No, connecting thread: M25 x 1.5, color: black
