

Housing - HC-STA-B10-SLWS-2SSM20-ELC-AL - 1412839

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Box mounting bases B10, With single locking latch, Material: Die-cast aluminum, salt water resistant, Cable outlets: 2, lateral, Height: 54.6 mm, Cable gland: none, Gland: no, 2x M20, Standard

Why buy this product

- good shielding in the event of electromagnetic interference



Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 060972
GTIN	4055626060972
Custom tariff number	85389099
Country of origin	Poland

Technical data

Dimensions

Height	54.6 mm
Width	52 mm
Length	92 mm

Ambient conditions

Degree of protection of housing (IP)	IP66
	IP67
Degree of protection of housing (NEMA)	4 (UL 50e)
	4X (UL 50e)

Housing - HC-STA-B10-SLWS-2SSM20-ELC-AL - 1412839

Technical data

Ambient conditions


	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

General

Note	For contact inserts HC-B10, BB18, DD42, M, K8/24
Size	B10
Housing type	Box mounting bases
Locking type	With single locking latch
No. of cable outlets	2
Cable exit	lateral
Screw connection	none
Type of the screw connection	2x M20
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	Uncoated
Seal material	NBR, conductive
Material lock	PA
Assembly instructions	One opening is sealed with a plastic filler plug and can be opened using a screwdriver.

Drawings

Dimensional drawing

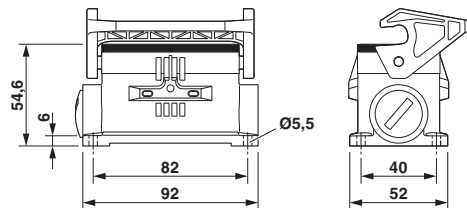

Dimensional drawing

Classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27143423
eCl@ss 8.0	27440202
eCl@ss 9.0	27440202

Housing - HC-STA-B10-SLWS-2SSM20-ELC-AL - 1412839

Classifications

ETIM

ETIM 5.0	EC000437
ETIM 6.0	EC000437

UNSPSC

UNSPSC 13.2	31261501
-------------	----------

Approvals


Approvals

Approvals


EAC / GL / UL Recognized / cUL Recognized / cULus Recognized


Ex Approvals

Approval details

EAC			7500651.22.01.00246
-----	---	--	---------------------

GL		http://exchange.dnv.com/tari/	6196614 HH
----	---	---	------------

UL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E255026
---------------	---	---	---------

cUL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E255026
----------------	---	---	---------

cULus Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	
------------------	---	---	--

Housing - HC-STA-B10-SLWS-2SSM20-ELC-AL - 1412839

Accessories

Accessories

Full screw connection

Cable gland - G-INS-M20-S68N-NNES-S - 1411163



Cable gland, Cable gland material: Nickel-plated brass, External cable diameter 6 mm ... 12 mm, Shielding: No, Connecting thread: M20, Color: silver

Cable gland - G-INSEC-M20-S68N-NCRS-S - 1411189



Cable gland, Cable gland material: Nickel-plated brass, External cable diameter 9 mm ... 13 mm, Shielding: yes, Connecting thread: M20, Color: silver

Cable gland - HC-M-KV-M20(1ASI) - 1584017



Metal screw connection for an AS-Interface flat-ribbon conductor, thread type M20

Housing latches

Replacement part - HC-STA-B10-SL-PLBK - 1412804



Single locking latch for B10 housing, HC-EVO...AL and HC-STA...AL

Seal

Housing - HC-STA-B10-SLWS-2SSM20-ELC-AL - 1412839

Accessories

Profile gasket - HC-B10-SP-CBK - 1411479



Profile gasket for HEAVYCON EVO supporting base element type B10, conductive
