

## Housing - HC-STA-B24-SLWD-2SSM32-ELC-AL - 1412874

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Box mounting bases B24, With double locking latch, Material: Die-cast aluminum, salt water resistant, Cable outlets: 2, lateral, Height: 68 mm, Cable gland: none, Gland: Yes, 2x M32, Standard

### Why buy this product

- good shielding in the event of electromagnetic interference



### Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 061238
GTIN	4055626061238
Weight per Piece (excluding packing)	340.000 g
Custom tariff number	85389099
Country of origin	Poland

### Technical data

#### Dimensions

Height	68 mm
Width	57 mm
Length	144 mm

#### Ambient conditions

Degree of protection of housing (IP)	IP66
	IP67
Degree of protection of housing (NEMA)	4 (UL 50e)

# Housing - HC-STA-B24-SLWD-2SSM32-ELC-AL - 1412874

## Technical data

### Ambient conditions


	4X (UL 50e)
	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

### General

Note	for contact inserts HC-B24, BB46, D64, DD108, HV10/16, M
Size	B24
Housing type	Box mounting bases
Locking type	With double locking latch
No. of cable outlets	2
Cable exit	lateral
Screw connection	none
Type of the screw connection	2x M32
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	Uncoated
Material lock	PA
Assembly instructions	One opening is sealed with a plastic filler plug and can be opened using a screwdriver.

## Drawings

Dimensional drawing

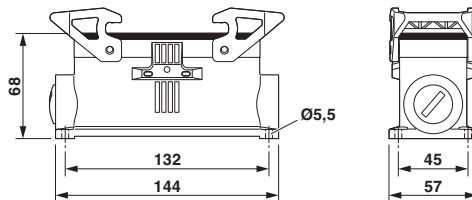

Dimensional drawing

## Classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27143423
eCl@ss 8.0	27440202
eCl@ss 9.0	27440202

# Housing - HC-STA-B24-SLWD-2SSM32-ELC-AL - 1412874

## Classifications

### ETIM

ETIM 5.0	EC000437
ETIM 6.0	EC000437

### UNSPSC

UNSPSC 13.2	31261501
-------------	----------

## Approvals


### Approvals

#### Approvals


EAC / GL / UL Recognized / cUL Recognized / cULus Recognized


#### Ex Approvals

### Approval details

EAC			7500651.22.01.00246
-----	---	--	---------------------

GL		<a href="http://exchange.dnv.com/tari/">http://exchange.dnv.com/tari/</a>	6196614 HH
----	---	---	------------

UL Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	E255026
---------------	---	---	---------

cUL Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	E255026
----------------	---	---	---------

cULus Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	
------------------	---	---	--

## Housing - HC-STA-B24-SLWD-2SSM32-ELC-AL - 1412874

### Accessories

#### Accessories

##### Full screw connection

Cable gland - G-INS-M32-M68N-NNES-S - 1411166



Cable gland, Cable gland material: Nickel-plated brass, External cable diameter 15 mm ... 21 mm, Shielding: No, Connecting thread: M32, Color: silver

---

Cable gland - G-INSEC-M32-M68N-NCRS-S - 1411191



Cable gland, Cable gland material: Nickel-plated brass, External cable diameter 14 mm ... 21 mm, Shielding: yes, Connecting thread: M32, Color: silver

---

### Housing latches

Housing brackets - HC-STA-B10-24-DL-PLBK - 1412886



Double locking latch for B10 / B16 / B24 housing, HC-EVO...AL and HC-STA...AL

---

### Seal

Profile gasket - HC-B24-SP-CBK - 1411482



Profile gasket for HEAVYCON EVO supporting base element type B24, conductive

---