

Housing - HC-STA-B24-SLWS-2SSP21-ELC-AL - 1412879

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




Box mounting bases B24, with single locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 2, lateral, height: 68 mm, cable gland: none, support sleeve: yes, 2x Pg21, Standard

Your advantages

- good shielding in the event of electromagnetic interference



Key Commercial Data

Packing unit	1 pc
GTIN	 4 055626 061283
GTIN	4055626061283
Weight per Piece (excluding packing)	340.000 g
Custom tariff number	85389099
Country of origin	China

Technical data

Dimensions

Height	68 mm
Width	57 mm
Length	144 mm

Ambient conditions

Degree of protection (IP)	IP66
	IP67
Degree of protection (NEMA)	4 (UL 50e)
	4X (UL 50e)

Housing - HC-STA-B24-SLWS-2SSP21-ELC-AL - 1412879

Technical data

Ambient conditions

	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

General


Note	for contact inserts HC-B24, BB46, D64, DD108, HV10/16, M
Size	B24
Housing type	Box mounting bases
Color	gray aluminum
Locking type	with single locking latch
No. of cable outlets	2
Cable outlet	lateral
Screw connection	none
Type of the screw connection	2x Pg21
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	uncoated
Seal material	NBR, conductive
Material lock	PA
Flammability rating according to UL 94	V0 (Interlock)
Assembly instructions	One opening is sealed with a plastic filler plug and can be opened using a screwdriver.

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

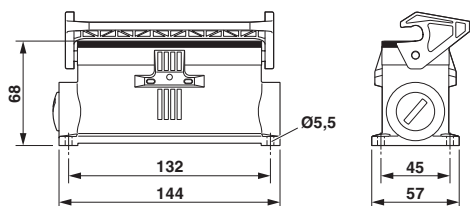

Dimensional drawing

Housing - HC-STA-B24-SLWS-2SSP21-ELC-AL - 1412879

Classifications

eCl@ss

eCl@ss 10.0.1	27440202
eCl@ss 11.0	27440202
eCl@ss 5.1	27261200
eCl@ss 6.0	27261200
eCl@ss 7.0	27440202
eCl@ss 9.0	27440202

ETIM

ETIM 6.0	EC000437
ETIM 7.0	EC000437

UNSPSC

UNSPSC 13.2	31261501
UNSPSC 18.0	31261501
UNSPSC 19.0	31261501
UNSPSC 20.0	31261501
UNSPSC 21.0	31261501

Approvals

Approvals

Approvals

UL Recognized / cUL Recognized / EAC / DNV GL / EAC / cULus Recognized

Ex Approvals

Approval details

UL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E255026
---------------	---	---	---------

cUL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E255026
----------------	---	---	---------

Housing - HC-STA-B24-SLWS-2SSP21-ELC-AL - 1412879

Approvals

EAC		RU C- DE.AI30.B.01102
-----	--	--------------------------

DNV GL		https://approvalfinder.dnvgl.com/	TAE000037S
--------	--	---	------------

EAC		RU C- DE.BL08.B.00511
-----	--	--------------------------

cULus Recognized		
------------------	--	--

Accessories

Accessories

Corrugated pipe screw connection

Screw connection - WP-G HF IP66 PG21 BK - 3240892



Cable gland, Pg thread, IP66 protection, straight

Screw connection - WP-G HF IP69K PG21 BK - 3240878



Cable gland, Pg thread, IP68/69k protection, straight

Housing - HC-STA-B24-SLWS-2SSP21-ELC-AL - 1412879

Accessories

Screw connection - WP-GA HF IP66 PG21 BK - 3240920



Cable gland, Pg thread, IP66 protection, angled

Screw connection - WP-GA HF IP69K PG21 BK - 3240906



Cable gland, Pg thread, IP68/69k protection, angled

Screw connection - WP-GR HF IP66 PG21 BK - 3240948



Cable gland, Pg thread, IP66 protection, with strain relief

Screw connection - WP-GR HF IP69K PG21 BK - 3240934



Cable gland, Pg thread, IP68/69k protection, with strain relief

Screw connection - WP-G PP HF PG21 - 3240992



Cable gland made from PP with Pg thread, IP65 protection

Housing - HC-STA-B24-SLWS-2SSP21-ELC-AL - 1412879

Accessories

Screw connection - WP-GT PP HF PG21 - 3241006



Cable gland made from PP with Pg thread, rotatable, IP54 protection

Screw connection - WP-G BRASS IP40 PG21 - 3241041



Cable gland made from brass with Pg thread, IP40 protection

Screw connection - WP-GT BRASS PG21 - 3241027



Cable gland made from brass with Pg thread, rotatable, IP40 protection

Screw connection - WP-G BRASS IP65 PG21 - 3241055



Cable gland made from brass with Pg thread, IP65 protection

Full screw connection

Cable gland - G-INS-PG21-M68N-NNES-S - 1411175



Cable gland, cable gland material: Nickel-plated brass, external cable diameter 13 mm ... 18 mm, shielding: no, connecting thread: Pg21, color: silver, with O-ring

Housing - HC-STA-B24-SLWS-2SSP21-ELC-AL - 1412879

Accessories

Cable gland - G-INSEC-PG21-M68N-NNES-S - 1411200



Cable gland, cable gland material: Nickel-plated brass, external cable diameter 13 mm ... 18 mm, shielding: yes, connecting thread: Pg21, color: silver, with O-ring

Housing latches

Replacement part - HC-STA-B24-SL-PLBK - 1412885



Single locking latch for B24 housing, HC-EVO....AL and HC-STA....AL

Seal

Profile gasket - HC-B24-SP-CBK - 1411482



Profile gasket for HEAVYCON EVO supporting base element type B24, conductive