

# Adapter - HC-B-TA-M20-PLR-BK - 1414243

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Adapter, plastic, for EVO housing, M20 thread



## Key Commercial Data

Packing unit	1 STK
GTIN	
GTIN	4055626021966
Weight per Piece (excluding packing)	20.800 g
Weight per piece (including packing)	20.800 g
Custom tariff number	85389099
Country of origin	Poland

## Technical data

### Dimensions

Length of internal thread	10 mm
---------------------------	-------

### Ambient conditions

Ambient temperature (operation)	-40 °C ... 100 °C
---------------------------------	-------------------

### General

Material	PA
Housing material	PA
Flammability rating according to UL 94	V0
Thread type on seal side	M20
Torque	6 Nm (Tightening torque of screw connection to be screwed in)
Assembly instructions	Bayonet locking max. 3x can be removed

### Standards and Regulations

Flammability rating according to UL 94	V0
--	----

# Adapter - HC-B-TA-M20-PLR-BK - 1414243

## Technical data

### Standards and Regulations


Assembly instructions	Bayonet locking max. 3x can be removed
-----------------------	--

### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

## Drawings

Dimensional drawing

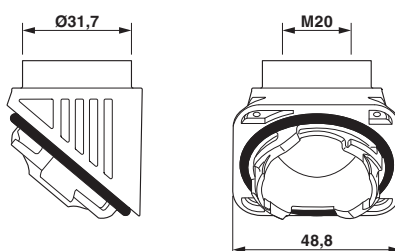

Dimensional drawing

## Classifications

### eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27261207
eCl@ss 8.0	27440209
eCl@ss 9.0	27440192

### ETIM

ETIM 5.0	EC002635
ETIM 6.0	EC002635

### UNSPSC

UNSPSC 13.2	39121408
-------------	----------

## Approvals

### Approvals

#### Approvals

UL Recognized / cUL Recognized / EAC / GL / cULus Recognized

#### Ex Approvals

# Adapter - HC-B-TA-M20-PLR-BK - 1414243

## Approvals

### Approval details

UL Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	E255026
cUL Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	E255026
EAC			RU C- DE.AI30.B.01102
GL		<a href="http://exchange.dnv.com/tari/">http://exchange.dnv.com/tari/</a>	6196614 HH
cULus Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	

## Accessories

### Accessories

#### Full screw connection

Cable gland - G-INS-M20-S68N-PNES-BK - 1411133



Cable gland, cable gland material: PA, external cable diameter 6 mm ... 12 mm, shielding: No, connecting thread: M20 x 1.5, color: jet black RAL 9005

Cable gland - G-INS-M20-M68N-PNES-BK - 1424481



Cable gland, cable gland material: PA, external cable diameter 10 mm ... 14 mm, shielding: No, connecting thread: M20 x 1.5, color: black

