

# Adapter - HC-B-TA-M32-PLR-BK - 1414245

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Adapter, plastic, for EVO housing, M32 thread



## Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 021980
GTIN	4055626021980
Weight per Piece (excluding packing)	23.500 g
Weight per piece (including packing)	26.600 g
Custom tariff number	85389099
Country of origin	Poland

## Technical data

### Dimensions

Length of internal thread	11 mm
---------------------------	-------

### Ambient conditions

Ambient temperature (operation)	-40 °C ... 100 °C
---------------------------------	-------------------

### General

Material	PA
Housing material	PA
Flammability rating according to UL 94	V0
Thread type on seal side	M32
Torque	10 Nm (Tightening torque of screw connection to be screwed in)
Assembly instructions	Bayonet locking max. 3x can be removed

## Standards and Regulations

Flammability rating according to UL 94	V0
--	----

# Adapter - HC-B-TA-M32-PLR-BK - 1414245


## Technical data

### Standards and Regulations

Assembly instructions	Bayonet locking max. 3x can be removed
-----------------------	--

## Drawings

Dimensional drawing

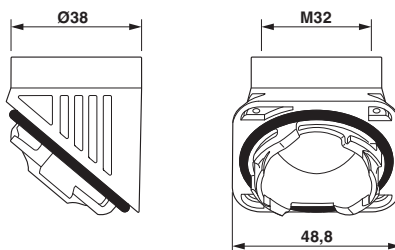

### Dimensional drawing

## Classifications

### eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27261207
eCl@ss 8.0	27440209
eCl@ss 9.0	27440192

### ETIM

ETIM 5.0	EC002635
ETIM 6.0	EC002635

### UNSPSC

UNSPSC 13.2	39121408
-------------	----------

## Approvals

### Approvals

#### Approvals

UL Recognized / cUL Recognized / EAC / GL / cULus Recognized

#### Ex Approvals

### Approval details

# Adapter - HC-B-TA-M32-PLR-BK - 1414245

## Approvals

UL Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	E255026
---------------	--	---	---------

cUL Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	E255026
----------------	--	---	---------

EAC			RU C- DE.AI30.B.01102
-----	--	--	--------------------------

GL		<a href="http://exchange.dnv.com/tari/">http://exchange.dnv.com/tari/</a>	6196614 HH
----	--	---	------------

cULus Recognized		<a href="http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm">http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm</a>	
------------------	--	---	--

## Accessories

### Accessories

#### Full screw connection

##### Cable gland - G-INS-M32-M68N-PNES-BK - 1411136



Cable gland, cable gland material: PA, external cable diameter 15 mm ... 21 mm, shielding: No, connecting thread: M32 x 1.5, color: jet black RAL 9005

##### Cable gland - G-INS-M32-L68N-PNES-BK - 1424483



Cable gland, cable gland material: PA, external cable diameter 18 mm ... 25 mm, shielding: No, connecting thread: M32 x 1.5, color: black