

Adapter - HC-B-TA-M20-ER-AL - 1414256


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Adapter, aluminum, for EVO housing, M20 thread



Key Commercial Data

| | |
|--------------------------------------|---|
| Packing unit | 1 STK |
| GTIN |  4 055626 022185 |
| GTIN | 4055626022185 |
| Weight per Piece (excluding packing) | 110.000 g |
| Custom tariff number | 85389099 |
| Country of origin | Germany |

Technical data

Dimensions

| | |
|---------------------------|-------|
| Length of internal thread | 13 mm |
|---------------------------|-------|

Ambient conditions

| | |
|---------------------------------|-------------------|
| Degree of protection | 4 (UL 50e) |
| | 4X (UL 50e) |
| | 12 (UL 50e) |
| Ambient temperature (operation) | -40 °C ... 125 °C |

General

| | |
|------------------|--|
| Material | Die-cast aluminum, corrosion-resistant |
| Housing material | Die-cast aluminum, corrosion resistant |

Adapter - HC-B-TA-M20-ER-AL - 1414256


Technical data

General

| | |
|--------------------------------|--|
| Thread type on connection side | Bayonet B metal |
| Thread type on seal side | M20 |
| Torque | 12 Nm (Tightening torque of screw connection to be screwed in) |

Drawings

Dimensional drawing

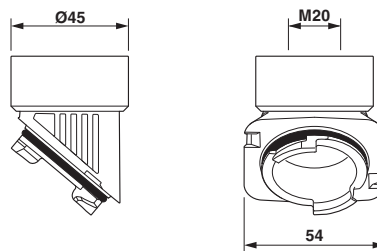

Dimensional drawing

Classifications

eCl@ss

| | |
|------------|----------|
| eCl@ss 5.1 | 27143424 |
| eCl@ss 6.0 | 27261207 |
| eCl@ss 8.0 | 27440209 |
| eCl@ss 9.0 | 27440209 |

ETIM

| | |
|----------|----------|
| ETIM 5.0 | EC002635 |
| ETIM 6.0 | EC002635 |

UNSPSC

| | |
|-------------|----------|
| UNSPSC 13.2 | 39121408 |
|-------------|----------|

Approvals

Approvals

Approvals





EAC / UL Recognized / cUL Recognized / cULus Recognized

Adapter - HC-B-TA-M20-ER-AL - 1414256

Approvals

Ex Approvals

Approval details

| | | | |
|------------------|---|---|---------------------|
| EAC |  | | 7500651.22.01.00246 |
| UL Recognized |  | http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm | E255026 |
| cUL Recognized |  | http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm | E255026 |
| cULus Recognized |  | http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm | |