

Adapter - HC-B-TA-PG29-ER-AL - 1414263


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Adapter, aluminum, for EVO housing, Pg29 thread



Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 022253
GTIN	4055626022253
Weight per Piece (excluding packing)	80.000 g
Custom tariff number	85389099
Country of origin	Germany

Technical data

Dimensions

Length of internal thread	13 mm
---------------------------	-------

Ambient conditions

Degree of protection	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

General

Material	Die-cast aluminum, corrosion-resistant
Housing material	Die-cast aluminum, corrosion resistant

Adapter - HC-B-TA-PG29-ER-AL - 1414263


Technical data

General

Thread type on connection side	Bayonet B metal
Thread type on seal side	Pg29
Torque	10 Nm (Tightening torque of screw connection to be screwed in)

Drawings

Dimensional drawing

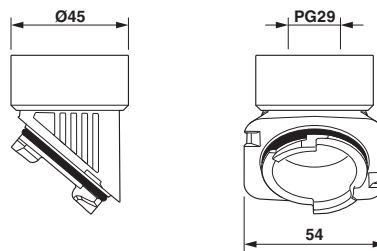

Dimensional drawing

Classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27261207
eCl@ss 8.0	27440209
eCl@ss 9.0	27440209

ETIM

ETIM 5.0	EC002635
ETIM 6.0	EC002635

UNSPSC

UNSPSC 13.2	39121408
-------------	----------

Approvals

Approvals

Approvals





EAC / UL Recognized / cUL Recognized / cULus Recognized

Adapter - HC-B-TA-PG29-ER-AL - 1414263

Approvals

Ex Approvals

Approval details

EAC			7500651.22.01.00246
UL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E255026
cUL Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	E255026
cULus Recognized		http://database.ul.com/cgi-bin/XYV/template/LISEXT/1FRAME/index.htm	