

## Protective covers - HC-B16-BCSFS-P-BK - 1414626

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON protective covers, B16, for HC-EVO-B16... supporting base element, for single locking latch, with retaining cord with combination eyelet, IP54



### Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 055626 030678
GTIN	4055626030678
Custom tariff number	85389099
Country of origin	Germany

### Technical data

#### Ambient conditions

Degree of protection	IP66
Ambient temperature (operation)	-20 °C ... 100 °C

#### General

Size	B16
Material	PA
Flammability rating according to UL 94	HB
Color	black
Seal present	no
Note	Protective cover for supporting base element with single locking latch
Connection	Plastic protective cover for short-term protection

# Protective covers - HC-B16-BCSFS-P-BK - 1414626

## Technical data

### Standards and Regulations


Flammability rating according to UL 94	HB
--	----

### Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

## Drawings

Dimensional drawing

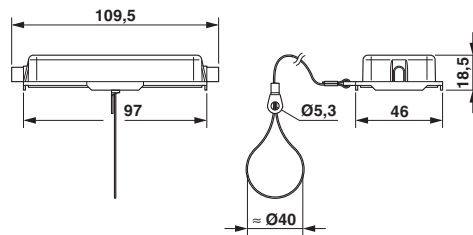

Dimensional drawing

## Classifications

eCl@ss

eCl@ss 5.1	23110102
eCl@ss 6.0	23110102
eCl@ss 8.0	27440208
eCl@ss 9.0	27440208

ETIM

ETIM 5.0	EC002314
ETIM 6.0	EC002314

UNSPSC

UNSPSC 13.2	39121421
-------------	----------

## Approvals

Approvals

Approvals

EAC

## Protective covers - HC-B16-BCSFS-P-BK - 1414626

### Approvals

---

Ex Approvals

---

### Approval details

EAC		7500651.22.01.00246
-----	---	---------------------

---

Phoenix Contact 2017 © - all rights reserved  
<http://www.phoenixcontact.com>