

Protective covers - HC-B24-BCSFD-P-BK - 1414630

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON protective cover, B24, for HC-EVO-B24... supporting base element, for double locking latch, with retaining cord with combination eyelet, IP54



Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 055626 030814
GTIN	4055626030814
Weight per Piece (excluding packing)	40.000 g
Custom tariff number	85389099
Country of origin	Germany

Technical data

Ambient conditions

Degree of protection	IP66
Ambient temperature (operation)	-20 °C ... 100 °C

General

Size	B24
Material	PA
Flammability rating according to UL 94	HB
Seal present	no
Note	Protective cover for supporting base element with double locking latch
Connection	Plastic protective cover for short-term protection

Protective covers - HC-B24-BCSFD-P-BK - 1414630


Technical data

Standards and Regulations

Flammability rating according to UL 94	HB
--	----

Drawings

Dimensional drawing

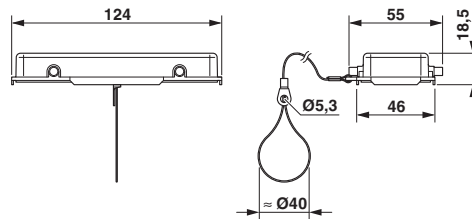

Dimensional drawing

Classifications

eCl@ss

eCl@ss 5.1	23110102
eCl@ss 6.0	23110102
eCl@ss 8.0	27440208
eCl@ss 9.0	27440208

ETIM

ETIM 5.0	EC002314
ETIM 6.0	EC002314

UNSPSC

UNSPSC 13.2	39121421
-------------	----------

Approvals

Approvals

Approvals


EAC

Ex Approvals

Protective covers - HC-B24-BCSFD-P-BK - 1414630

Approvals

Approval details

EAC		7500651.22.01.00246
-----	---	---------------------