

## Protective covers - HC-B24-HCLFD-PR-BK - 1414633


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



HEAVYCON protective cover, B24, for HC-ECO-B24... sleeve housing, for double locking latch, with retaining cord, IP54, with seal



### Key Commercial Data

Packing unit	1
GTIN	 4 055626 030852
GTIN	4055626030852
Custom tariff number	85389099

### Technical data

#### Dimensions

Diameter of retaining cord eyelet	30 mm
-----------------------------------	-------

#### Ambient conditions

Degree of protection	IP54
	IP66 (for housing HC-STA.../ HC-EVO...PL)
Ambient temperature (operation)	-20 °C ... 100 °C

#### General

Size	B24
Material	PA
Seal material	NBR
Flammability rating according to UL 94	HB
Seal present	yes
Note	Protective cover for supporting base element with double locking latch

# Protective covers - HC-B24-HCLFD-PR-BK - 1414633

## Technical data

### General


Connection	Plastic protective cover for short-term protection
------------	--

### Standards and Regulations

Flammability rating according to UL 94	HB
--	----

## Drawings

Dimensional drawing

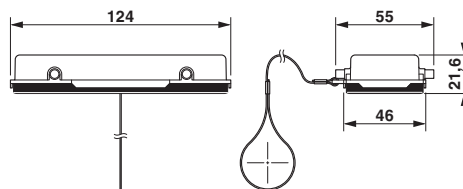

Dimensional drawing

## Classifications

### eCl@ss

eCl@ss 5.1	23110102
eCl@ss 6.0	23110102
eCl@ss 8.0	27440208
eCl@ss 9.0	27440208

### ETIM

ETIM 5.0	EC002314
ETIM 6.0	EC002314

### UNSPSC

UNSPSC 13.2	39121421
-------------	----------

## Approvals

### Approvals

Approvals

EAC

## Protective covers - HC-B24-HCLFD-PR-BK - 1414633

### Approvals

Ex Approvals

---

#### Approval details

EAC		7500651.22.01.00246
-----	---	---------------------