

Cable gland - HC-B-GM5X8,5-M40-ET-AL - 1414649

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)




EVO metal cable gland with bayonet locking; size M40, for 5 conductors with 8.5 mm cable diameter

Product Description

Metal cable gland

Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 031019
GTIN	4055626031019
Weight per Piece (excluding packing)	140.000 g
Custom tariff number	85389099
Country of origin	Germany

Technical data

Dimensions

External cable diameter	8.5 mm (Cable 1 ... 5)
-------------------------	------------------------

Ambient conditions

Degree of protection	IP66 (Cable diameter 8.5 mm +/-0.1 mm)
	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Ambient temperature (operation)	-30 °C ... 100 °C

General

Cable gland - HC-B-GM5X8,5-M40-ET-AL - 1414649


Technical data

General

Type of the screw connection	M40
No. of conductors	5
Material	Die-cast aluminum, corrosion-resistant
Housing material	Die-cast aluminum, corrosion resistant
Cable gland material	Aluminum
Material, pressure screw	Brass
Shielded	No
Thread type on connection side	Bayonet B metal

Drawings

Dimensional drawing

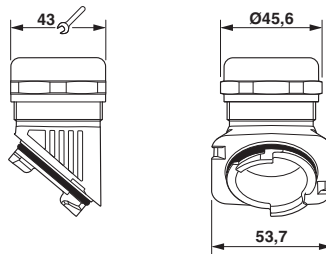

Dimensional drawing

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		7500651.22.01.00246
-----	--	---------------------

