

Cable gland - HC-B-GTRS-M20-ER-AL - 1414656


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Set consisting of: EVO metal adapter 1414256 and metal screw connection with terminal block 1415192, M20



Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 031071
GTIN	4055626031071
Weight per Piece (excluding packing)	180.000 g
Custom tariff number	85389099
Country of origin	Germany

Technical data

Dimensions

Wrench size, union nut	24 mm
Wrench size, support	24 mm
External cable diameter	6 mm ... 13 mm

Ambient conditions

Degree of protection	IP66
	IP67
Ambient temperature (operation)	-40 °C ... 100 °C

General

Type of the screw connection	M20
No. of conductors	1

Cable gland - HC-B-GTRS-M20-ER-AL - 1414656


Technical data

General

Cable gland material	Nickel-plated brass
Material, pressure screw	Nickel-plated brass
Shielded	No
Thread type on connection side	Bayonet B metal

Drawings

Dimensional drawing

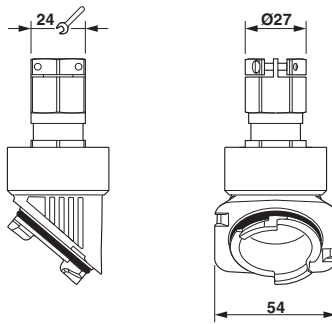

Dimensional drawing

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		7500651.22.01.00246
-----	--	---------------------