

Cable gland - HC-B-GTRS-M25-ER-AL - 1414657

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Set consisting of: EVO metal adapter 141425 and screw connection with terminal block 1415193, M25



Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 031088
GTIN	4055626031088
Custom tariff number	85389099
Country of origin	Germany

Technical data

Dimensions

Wrench size, union nut	29 mm
Wrench size, support	29 mm
External cable diameter	9 mm ... 17 mm

Ambient conditions

Degree of protection	IP66
	IP67
Ambient temperature (operation)	-40 °C ... 100 °C

General

Type of the screw connection	M25
No. of conductors	1
Cable gland material	Nickel-plated brass

Cable gland - HC-B-GTRS-M25-ER-AL - 1414657


Technical data

General

Material, pressure screw	Nickel-plated brass
Shielded	No
Thread type on connection side	Bayonet B metal

Drawings

Dimensional drawing

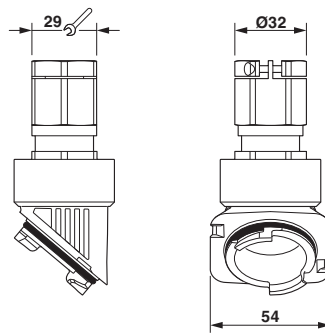

Dimensional drawing

Classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27261207
eCl@ss 8.0	27149109
eCl@ss 9.0	27144432

ETIM

ETIM 5.0	EC000441
ETIM 6.0	EC000441

UNSPSC

UNSPSC 13.2	39121311
-------------	----------

Approvals

Approvals

Cable gland - HC-B-GTRS-M25-ER-AL - 1414657

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		7500651.22.01.00246
-----	---	---------------------
