

Cable gland - HC-B-GB-M20-PLRBK - 1414660

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Set consisting of: EVO plastic adapter 1414243 and plastic screw connection with bending armor rod 1415179, M20



Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 031118
GTIN	4055626031118
Weight per Piece (excluding packing)	40.000 g
Custom tariff number	39269097
Country of origin	Poland

Technical data

Dimensions

Wrench size, union nut	24 mm
Wrench size, support	24 mm
External cable diameter	6 mm ... 13 mm

Ambient conditions

Ambient temperature (operation)	-40 °C ... 100 °C
---------------------------------	-------------------

General

Type of the screw connection	M20
No. of conductors	1
Material	PA
Housing material	PA

Cable gland - HC-B-GB-M20-PLRBK - 1414660


Technical data

General

Cable gland material	PA
Shielded	No
Thread type on connection side	Bayonet B plastic

Drawings

Dimensional drawing

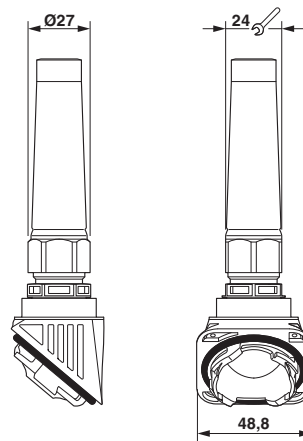

Dimensional drawing

Classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27261207
eCl@ss 8.0	27149109
eCl@ss 9.0	27144432

ETIM

ETIM 5.0	EC000441
ETIM 6.0	EC000441

UNSPSC

UNSPSC 13.2	39121311
-------------	----------

Approvals

Approvals

Cable gland - HC-B-GB-M20-PLRBK - 1414660

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		7500651.22.01.00246
-----	-----------------------------------------------------------------------------------	---------------------
