

Screw plug - A-INSP-M25-65N-P-BK - 1415207

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Screw plug, Cable gland material: PA, Connecting thread: M25, Color: jet black RAL 9005



Key Commercial Data

Packing unit	1 STK
Minimum order quantity	10 STK
GTIN	 4 055626 038520
GTIN	4055626038520
Weight per Piece (excluding packing)	6.000 g
Custom tariff number	39269097
Country of origin	Germany

Technical data

Dimensions

Length	11.5 mm
Length without connecting thread	3.5 mm
Connecting thread diameter	25 mm
Hexagon angular dimension	30 mm (Diameter)
Length of the connecting thread	8 mm

Ambient conditions

Degree of protection	IP68
	IP66
Ambient temperature (operation)	-40 °C ... 100 °C

Screw plug - A-INSP-M25-65N-P-BK - 1415207

Technical data

General


Cable gland material	PA
Thread type on connection side	M25
Thread pitch	1.5 mm
Color	jet black RAL 9005

Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

Drawings

Dimensional drawing

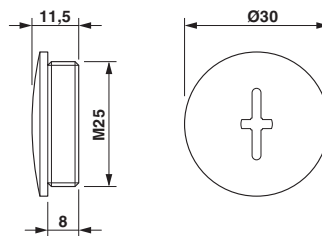

Classifications

eCl@ss

eCl@ss 5.1	27149109
eCl@ss 6.0	27149109
eCl@ss 8.0	23111190
eCl@ss 9.0	23111190

ETIM

ETIM 4.0	EC000032
ETIM 5.0	EC000032
ETIM 6.0	EC000032

UNSPSC

UNSPSC 13.2	31161501
-------------	----------

Accessories

Accessories

Flat nut

Screw plug - A-INSP-M25-65N-P-BK - 1415207

Accessories

Nut - A-INL-M25-P-BK - 1411216



Nut, PA, for threads M25, Color: jet black RAL 9005