

## Extension adapter - A-INE-PG16/21-N-NS-S - 1415220


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Extension adapter, Cable gland material: Nickel-plated brass, Nickel-plated brass, Connecting thread: Pg16, Color: silver



### Key Commercial Data

Packing unit	1
GTIN	 4 055626 038636
GTIN	4055626038636
Custom tariff number	74153900

### Technical data

#### Dimensions

Length	21 mm
Length without connecting thread	14.5 mm
Connecting thread diameter	23 mm
Hexagon angular dimension	30 mm
Length of the connecting thread	6.5 mm

#### Ambient conditions

Degree of protection	IP65 (Depends on the screw connection used)
Ambient temperature (operation)	-20 °C ... 80 °C

#### General

Material	Nickel-plated brass
Cable gland material	Nickel-plated brass
O-ring material	NBR

## Extension adapter - A-INE-PG16/21-N-NS-S - 1415220


### Technical data

#### General

Outer thread	Pg16
Internal thread	Pg21
Color	silver

### Drawings

Dimensional drawing

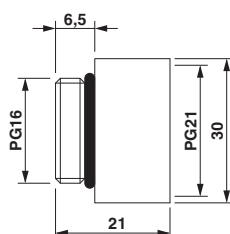

### Classifications

#### eCl@ss

eCl@ss 5.1	27149109
eCl@ss 6.0	27149109
eCl@ss 8.0	27379201
eCl@ss 9.0	27379201

#### ETIM

ETIM 5.0	EC002498
ETIM 6.0	EC002498

#### UNSPSC

UNSPSC 13.2	39121421
-------------	----------