

## DIN rail adapter - CUC-PP-D1PGY/R4GC8 - 1418094

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



DIN rail adapter, Degree of protection: IP20, Number of positions: 8, 1 Gbps, CAT6, Connection method: Coupling

### Product Description

Freenet system

### Why buy this product

- DIN rail mounting



### Key Commercial Data

Packing unit	1 STK
Weight per Piece (excluding packing)	60.000 g
Custom tariff number	85366990
Country of origin	Taiwan

### Technical data

#### Mechanical characteristics

Number of positions	8
Number of slots	2
Connection profile	RJ45
Insertion/withdrawal cycles	≥ 750
Connection method	Coupling
Color	gray
Degree of protection	IP20

#### Ambient conditions

Ambient temperature (operation)	-10 °C ... 60 °C
Ambient temperature (storage/transport)	-40 °C ... 70 °C

# DIN rail adapter - CUC-PP-D1PGY/R4GC8 - 1418094

## Technical data

### Material data

Flammability rating according to UL 94	V0
----------------------------------------	----

### Electrical characteristics


Number of positions	8
GRP transmission properties	CAT6
Transmission speed	1 Gbps
Frequency range	250 MHz

### Standards and Regulations

Flammability rating according to UL 94	V0
----------------------------------------	----


## Drawings

Dimensional drawing

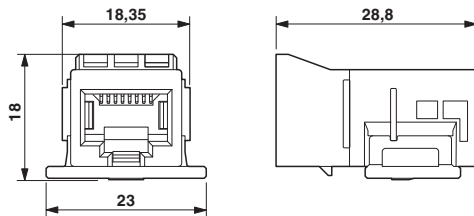

RJ45 socket insert, Freenet system

Dimensional drawing

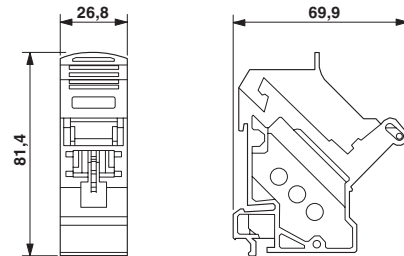

RJ45 patch panel

## Classifications

### eCl@ss

eCl@ss 4.0	272607XX
eCl@ss 4.1	27260701
eCl@ss 5.0	19030109
eCl@ss 5.1	19030109
eCl@ss 6.0	19170107
eCl@ss 7.0	19170112
eCl@ss 8.0	19170112
eCl@ss 9.0	27060308

### ETIM

ETIM 3.0	EC001128
ETIM 4.0	EC001128
ETIM 5.0	EC002599

# DIN rail adapter - CUC-PP-D1PGY/R4GC8 - 1418094

## Classifications

### UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	31261501

## Approvals

### Approvals

---

Approvals

EAC

---

Ex Approvals

---

### Approval details

EAC B.01742
-------------

## Accessories

### Accessories

#### Assembly adapter

Adapter - FL DIN RA - 2891053



The FL DIN RA is installed in a standard, 19-inch rack (EIA-310-D, IEC 60297-3-100) to allow DIN rail mounted equipment to be rack mounted.

### Female insert

---

## DIN rail adapter - CUC-PP-D1PGY/R4GC8 - 1418094

### Accessories

RJ45 coupling - CUC-F-D1ZNI-S/R4GC8 - 1419022



RJ45 coupling, Degree of protection: IP20, Number of positions: 8, 1 Gbps, CAT6, Material: Zinc die-cast

---

---