

Housing - HC-STA-D07-HHFS-1SM20-EL-AL - 1419235

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Sleeve housing D7, for single locking latch, Material: Die-cast aluminum, salt water resistant, Cable outlets: 1, lateral, Height: 48 mm, Cable gland: none, Gland: Yes, 1x M20, Standard



Key Commercial Data

Packing unit	1 STK
Custom tariff number	85389099
Country of origin	China

Technical data

Dimensions

Height	48 mm
Width	28 mm
Length	26.5 mm

Ambient conditions

Degree of protection of housing (IP)	IP54
	IP65 (with sealing screw)
Ambient temperature (operation)	-40 °C ... 125 °C

General

Note	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
Size	D7
Housing type	Sleeve housing
Locking type	for single locking latch
No. of cable outlets	1
Cable exit	lateral

Housing - HC-STA-D07-HHFS-1SM20-EL-AL - 1419235


Technical data

General

Screw connection	none
Type of the screw connection	1x M20
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	Uncoated

Drawings

Dimensional drawing

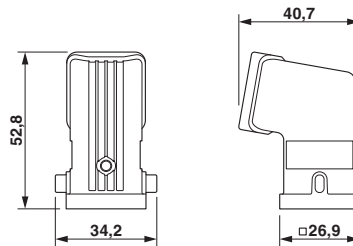

Classifications

eCl@ss

eCl@ss 5.1	27260701
eCl@ss 8.0	27440202
eCl@ss 9.0	27440202

ETIM

ETIM 5.0	EC000437
----------	----------

Accessories

Accessories

Extension adapter

Extension adapter - ENLAR-M-KV-M20/M25 - 1647666



Step-up adapter, M20 to M25, including O-ring

Full screw connection

Housing - HC-STA-D07-HHFS-1SM20-EL-AL - 1419235

Accessories

Cable gland - G-INS-M20-S68N-PNES-GY - 1411125



Cable gland, Cable gland material: Polyamide 6, External cable diameter 6 mm ... 12 mm, Shielding: No, Connecting thread: M20, Color: silver-gray RAL 7001

Cable gland - G-INS-M20-S68N-PNES-BK - 1411133



Cable gland, Cable gland material: Polyamide 6, External cable diameter 6 mm ... 12 mm, Shielding: No, Connecting thread: M20, Color: jet black RAL 9005

Cable gland - G-INS-M20-S68N-NNES-S - 1411163



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 6 mm ... 12 mm, Shielding: No, Connecting thread: M20, Color: silver

Cable gland - HC-M-KV-M20(11-16) - 1645998



Metal screw connection up to 5 bar, thread length: 6 mm, cable diameter: 11 - 16 mm, WAF 27, screw connection: M20

Cable gland - G-INSEC-M20-S68N-NCRS-S - 1411189



Cable gland, Cable gland material: Brass, nickel-plated, External cable diameter 9 mm ... 13 mm, Shielding: yes, Connecting thread: M20, Color: silver

Housing - HC-STA-D07-HHFS-1SM20-EL-AL - 1419235

Accessories

Cable gland - HC-M-KV-Z-M20 - 1646146



Metal screw connection with strain relief clamp, thread length: 6 mm, cable sealing area: 7.5 - 15 mm, clamping area: 11 - 17 mm, SW 24, screw connection: M20

Cable gland - HC-M-KV-T-M20 - 1646188



Metal screw connection with cable bend protection and strain relief, thread length: 6 mm, cable sealing area: 7.5 - 15 mm, clamping area: 10 - 16 mm, SW 24, screw connection: M20

Half screw connection

Pressure screw set - HC-M-DE-M20 - 1647967



Pressure screw set, for housing with M20 thread and glands, consisting of notched seal, 2 washers and pressure screw, cable diameter 4 - 13 mm, SW 20

Plug for cable screw gland

Filler plugs - HC-M-BS-M20 - 1645846



Filler plug, metal, size: M20

Reducing adapter

Housing - HC-STA-D07-HHFS-1SM20-EL-AL - 1419235

Accessories

Reducing adapter - REDUC-M-KV-M20/M16 - 1647611



Step-down adapter, M20 to M16, including O-ring