

Housing - HC-STA-D07-CHWS-1TTM20-EL-AL - 1419238


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Coupling housings D7, With single locking latch, Material: Die-cast aluminum, salt water resistant, Cable outlets: 1, straight, Height: 60.5 mm, Cable gland: none, Gland: Yes, 1x M20, Standard



Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 159713
GTIN	4055626159713
Custom tariff number	85389099
Country of origin	China

Technical data

Dimensions

Height	60.5 mm
Width	26.5 mm
Length	26.5 mm

Ambient conditions

Degree of protection of housing (IP)	IP66
	IP67
Degree of protection of housing (NEMA)	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

General

Housing - HC-STA-D07-CHWS-1TTM20-EL-AL - 1419238


Technical data

General

Note	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
Size	D7
Housing type	Coupling housings
Locking type	With single locking latch
No. of cable outlets	1
Cable exit	straight
Screw connection	none
Type of the screw connection	1x M20
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	Uncoated

Drawings

Dimensional drawing

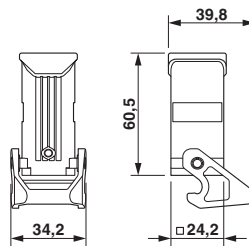

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC



EAC-Zulassung

