

Housing - HC-STA-D07-CHWSCM-1TTP11-EL-AL - 1419248


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Coupling housings D7, With single locking latch, Material: Die-cast aluminum, salt water resistant, Cable outlets: 1, straight, Height: 60.5 mm, Cable gland: none, Gland: Yes, 1x Pg11, Standard, for pin inserts



Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 159799
GTIN	4055626159799
Custom tariff number	85389099
Country of origin	China

Technical data

Dimensions

Height	60.5 mm
Width	34.2 mm
Length	24.2 mm

Ambient conditions

Degree of protection of housing (IP)	IP66
	IP67
Degree of protection of housing (NEMA)	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

Housing - HC-STA-D07-CHWSCM-1TTP11-EL-AL - 1419248


Technical data

General

Note	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
Size	D7
Housing type	Coupling housings
Locking type	With single locking latch
No. of cable outlets	1
Cable exit	straight
Screw connection	none
Type of the screw connection	1x Pg11
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	Uncoated

Drawings

Dimensional drawing

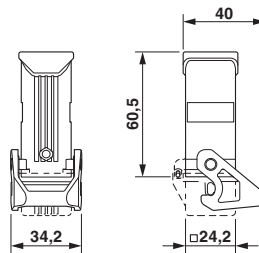

Classifications

eCl@ss

eCl@ss 5.1	27269202
eCl@ss 8.0	27440202
eCl@ss 9.0	27440202

ETIM

ETIM 5.0	EC000437
ETIM 6.0	EC000437

UNSPSC

UNSPSC 13.2	31261501
-------------	----------

Accessories

Accessories

Housing - HC-STA-D07-CHWSCM-1TTP11-EL-AL - 1419248

Accessories

Full screw connection

Cable gland - G-INS-PG11-S68N-NNES-S - 1411172



Cable gland, Cable gland material: Nickel-plated brass, External cable diameter 5 mm ... 10 mm, Shielding: No, Connecting thread: Pg11, Color: silver

Cable gland - G-INSEC-PG11-S68N-NNES-S - 1411197



Cable gland, Cable gland material: Nickel-plated brass, External cable diameter 5 mm ... 10 mm, Shielding: yes, Connecting thread: Pg11, Color: silver

Cable gland - G-INS-PG11-S68N-PNES-GY - 1411142



Cable gland, Cable gland material: PA, External cable diameter 5 mm ... 10 mm, Shielding: No, Connecting thread: Pg11, Color: silver-gray RAL 7001

Cable gland - G-INS-PG11-M68N-PNES-BK - 1424497



Cable gland, Cable gland material: PA, External cable diameter 5 mm ... 10 mm, Shielding: No, Connecting thread: Pg11, Color: jet black RAL 9005

Housing latches

Housing brackets - HC-D07-SL-PLBK - 1424440



Housing - HC-STA-D07-CHWSCM-1TTP11-EL-AL - 1419248

Accessories

Labeled device marker

Plastic label - US-EMLP (20X9) CUS - 0830085



Plastic label, can be ordered: By card, white, labeled according to customer specifications, Mounting type: Adhesive, Lettering field: 20 x 9 mm
