

## Housing - HC-STA-D07-BWS-EL-AL - 1419249

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Panel mounting base D7, With single locking latch, Material: Die-cast aluminum, salt water resistant, Height: 24 mm, Cable gland: none, Gland: no, Standard



### Key Commercial Data

Packing unit	1 STK
Weight per Piece (excluding packing)	20.000 g
Custom tariff number	85389099
Country of origin	China

### Technical data

#### Dimensions

Height	24 mm
Width	38 mm
Length	28 mm
Length of the assembly cutout	21.5 mm
Width of the assembly cutout	21.5 mm

#### Ambient conditions

Degree of protection of housing (IP)	IP54
	IP65 (with sealing screw)
Ambient temperature (operation)	-40 °C ... 125 °C

#### General

Note	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
Size	D7

# Housing - HC-STA-D07-BWS-EL-AL - 1419249


## Technical data

### General

Housing type	Panel mounting base
Locking type	With single locking latch
Screw connection	none
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	Uncoated

## Drawings

Dimensional drawing

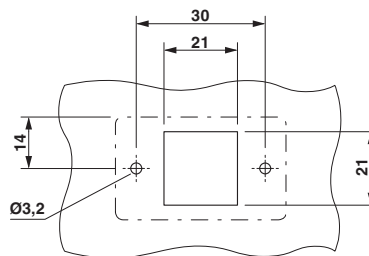

Panel cutout

## Classifications

eCl@ss

eCl@ss 5.1	27269202
eCl@ss 8.0	27440202
eCl@ss 9.0	27440202

ETIM

ETIM 5.0	EC000437
----------	----------

## Accessories

Accessories

Mounting material

Sealing screw - HC-D 7-DS-IP65 - 1686229



Sealing screw, Size: Countersunk head

# Housing - HC-STA-D07-BWS-EL-AL - 1419249

## Accessories

---

---

Phoenix Contact 2016 © - all rights reserved  
<http://www.phoenixcontact.com>