

Housing - HC-STA-D07-BAWS-PL-BK - 1419266

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Panel mounting base D7, With single locking latch, Material: Polyamide, Height: 25.5 mm, Cable gland: none, Gland: no, Standard

RoHS

Key Commercial Data

Packing unit	1 STK
Weight per Piece (excluding packing)	20.000 g
Custom tariff number	85389099
Country of origin	China

Technical data

Dimensions

Height	25.5 mm
Width	40.5 mm
Length	38 mm
Length of the assembly cutout	21.5 mm
Width of the assembly cutout	21.5 mm

Ambient conditions

Degree of protection of housing (IP)	IP54
	IP65 (with sealing screw)
Ambient temperature (operation)	-40 °C ... 125 °C

General

Note	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
Size	D7
Housing type	Panel mounting base

Housing - HC-STA-D07-BAWS-PL-BK - 1419266


Technical data

General


Color	black
Locking type	With single locking latch
Screw connection	none
Housing material	Polyamide
Seal material	NBR
Material lock	Polyamide

Drawings

Dimensional drawing

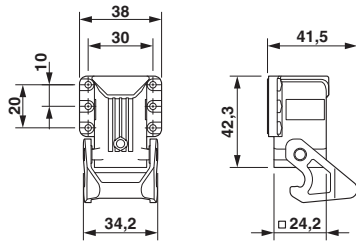

Dimensional drawing

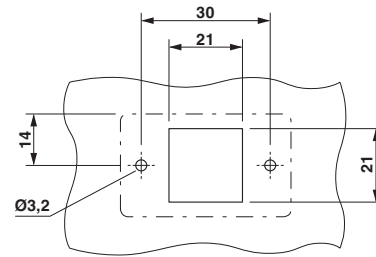

Panel cutout

Classifications

eCl@ss

eCl@ss 5.1	27260701
eCl@ss 8.0	27440202
eCl@ss 9.0	27440202

ETIM

ETIM 5.0	EC000437
----------	----------

Accessories

Accessories

Mounting material

Housing - HC-STA-D07-BAWS-PL-BK - 1419266

Accessories

Sealing screw - HC-D 7-DS-IP65 - 1686229



Sealing screw, Size: Countersunk head