

## Housing - HC-STA-D07-SHOWS-1SGM20-PL-BK - 1419267


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Box mounting bases D7, With single locking latch, Material: PA, Cable outlets: 1, lateral, Height: 27.9 mm, Cable gland: with, Gland: no, 1x M20, Standard, open floor

RoHS

### Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 160184
GTIN	4055626160184
Custom tariff number	85389099
Country of origin	China

### Technical data

#### Dimensions

Height	27.9 mm
Width	38 mm
Length	24.2 mm
External cable diameter	4 mm ... 10 mm

#### Ambient conditions

Degree of protection of housing (IP)	IP66
Degree of protection of housing (NEMA)	12 (UL 50e)
Ambient temperature (operation)	-40 °C ... 125 °C

#### General

Note	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
Size	D7

# Housing - HC-STA-D07-SHOWS-1SGM20-PL-BK - 1419267


## Technical data

### General

Housing type	Box mounting bases
Color	black
Locking type	With single locking latch
No. of cable outlets	1
Cable exit	lateral
Screw connection	with
Type of the screw connection	1x M20
Housing material	PA
Seal material	NBR
Material lock	PA

## Drawings

Dimensional drawing

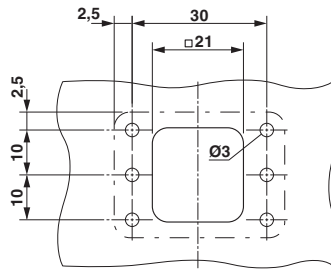

Panel cutout

## Approvals

Approvals

---

Approvals

EAC

---

Ex Approvals

---

Approval details

# Housing - HC-STA-D07-SHOWS-1SGM20-PL-BK - 1419267

## Approvals

EAC		EAC-Zulassung
-----	---	---------------