

Protective covers - HC-STA-D07-HCLWS-PLR-BK - 1419274


Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Protective cover D7, With single locking latch, Material: PA, Protective cover material: PA, Height: 30 mm, Seal: yes, Standard, With lanyard, Diameter of retaining cord eyelet: 25 mm, for socket inserts



Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 160252
GTIN	4055626160252
Custom tariff number	85389099
Country of origin	China

Technical data

Dimensions

Height	30 mm
Width	24.2 mm
Length	24.2 mm

Ambient conditions

Degree of protection of housing (IP)	IP66
Ambient temperature (operation)	-20 °C ... 100 °C

General

Size	D7
Type	For sleeve housing without single locking latch
Housing type	Protective cover
Color	black

Protective covers - HC-STA-D07-HCLWS-PLR-BK - 1419274

Technical data

General


Locking type	With single locking latch
Housing material	PA
Seal material	NBR
Material lock	PA
Material, protective cover	PA
Flammability rating according to UL 94	V0
Connection	Plastic protective cover for short-term protection

Standards and Regulations

Flammability rating according to UL 94	V0
--	----

Drawings

Dimensional drawing

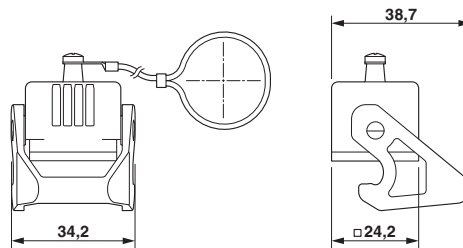

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		EAC-Zulassung
-----	--	---------------

