

Housing - HC-STA-D07-BWSCM-PL-BK - 1419278

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Panel mounting base D7, With single locking latch, Material: PA, Protective cover material: PA, Height: 25.5 mm, Cable gland: none, Gland: no, Protective cover: Yes, Standard, for pin inserts

RoHS

Key Commercial Data

Packing unit	1 STK
GTIN	
GTIN	4055626160283
Weight per Piece (excluding packing)	20.000 g
Custom tariff number	85389099
Country of origin	China

Technical data

Dimensions

Height	25.5 mm
Width	34.2 mm
Length	24.2 mm

Ambient conditions

Degree of protection of housing (IP)	IP66
Degree of protection of housing (NEMA)	12 (UL 50e)
Ambient temperature (operation)	-20 °C ... 100 °C

General

Note	for contact inserts HC-A03, A04, D07, D08, Q02, Q03, Q04, Q05, Q07, Q12
Size	D7

Housing - HC-STA-D07-BWSCM-PL-BK - 1419278


Technical data

General


Housing type	Panel mounting base
Color	black
Locking type	With single locking latch
Screw connection	none
Protective cover	Yes
Housing material	PA
Material lock	PA
Material, protective cover	PA

Drawings

Dimensional drawing

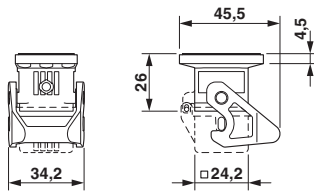

Dimensional drawing

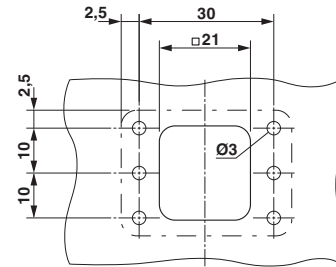

Panel cutout

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		EAC-Zulassung
-----	--	---------------

