

Contact insert module - HC-M-RJ45-08-GC-F/F - 1419886

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Contact insert module, Number of positions: RJ45, Type: RJ45, Socket, Application: Data, Gender changer



Key Commercial Data

Packing unit	1 STK
GTIN	 4 055626 253244
GTIN	4055626253244
Weight per Piece (excluding packing)	20.000 g
Custom tariff number	85366990
Country of origin	Poland

Technical data

Dimensions

Height	36.7 mm
--------	---------

Electrical characteristics

Connection profile	RJ45
Transmission characteristics (category)	CAT6 _A (IEC 60512-27-100:2008, TIA-568-C.2:2009)

Ambient conditions

Ambient temperature (operation)	-40 °C ... 70 °C
---------------------------------	------------------

General

Type	RJ45
Number of module slots	1
Flammability rating according to UL 94	V0

Contact insert module - HC-M-RJ45-08-GC-F/F - 1419886

Technical data

General


Degree of pollution	3
Overvoltage category	III

Standards and Regulations

Flammability rating according to UL 94	V0
--	----

Drawings

Dimensional drawing

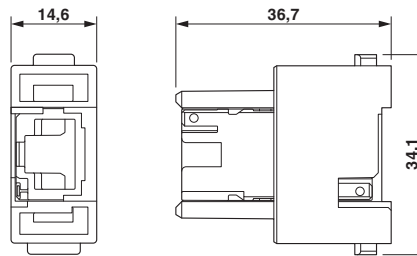

Female insert

Approvals

Approvals

Approvals

EAC

Ex Approvals

Approval details

EAC		7500651.22.01.00246
-----	--	---------------------